

Thread Install Rod Hanger with Angle Bracket



VLASTNOSTI

Suspends threaded rod from horizontal structures such as laminated wood or concrete beams, joists, ceilings and walls

SPECIFIKACE

Povrchová úprava: nVent CADDY Armour;Pregalvanized

Materiál: Spring Ocel;Ocel

Table 1/1


| Katalogové číslo | Article Number | Hole Size 1 (HS1) | Hole Type 1 | Hole Size 2 (HS2) | Hole Type 2 | Static Load |
|------------------|----------------|-------------------|-------------|-------------------|-------------|-------------|
| M6TIB | 174850 | 7 mm | Plain | 6 mm | Threaded | 700N |
| M8TIB | 174940 | 7 mm | Plain | 8 mm | Threaded | 700N |
| M10TIB | 175030 | 7 mm | Plain | 10 mm | Threaded | 700N |

DALŠÍ PODROBNOSTI O PRODUKTU

Loads indicated are for nVent CADDY Fasteners only.

Method of attachment to structure must be evaluated separately.

DIAGRAMS

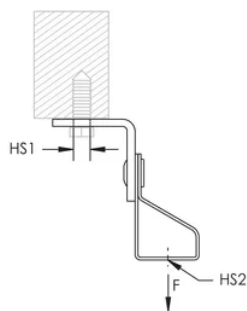

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

