

FleXbus IP55 Conductor Entry, Single Entry, 176 mm x 102 mm x 152 mm

Data Solutions

KATALOGOVÉ ČÍSLO

FLEXCEIP55C1001



nVent ERIFLEX FleXbus IP55 Conductor Entries can be used for switchboard and/or power supply cover to upgrade an installation to IP55 level. Protect the nVent ERIFLEX FleXbus Conductor insulation against sharp edges from power supply or switchboard top cover.

CERTIFICATIONS



VLASTNOSTI

Made with soft PVC to follow any potential conductor bending radius

Sealing around the conductor is made by a self-fusing tape with a strong adhesive

Good resistance to solvent and hydrocarbon splashes

Adaptable to any nVent ERIFLEX FleXbus conductor cross section by cutting the top material with traditional cutter

High acid resistance

UV resistance

RoHS compliant

Flame retardant

VLASTNOSTI PRODUKTU

Article Number: 508141

Materiál: Polyvinylchloride

Enclosure Rating: IP 55

Typ: Single Entry

Working Temperature: -40 to 140°C

A: 176mm

B: 102mm


C: 152mm

Conductor Size: 960 mm²; 1280 mm²; 1810 mm²

Torque (TQ): 2.5N·m

Unit Weight: 0.7kg

DIAGRAMS

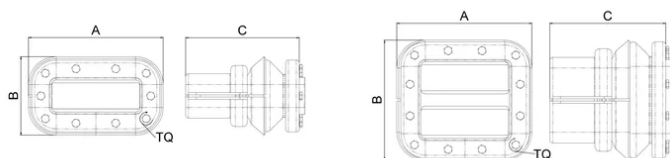

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTÉ