

Four Pole Distrib. Block with Threaded Bars, 250 A

Data Solutions

KATALOGOVÉ ČÍSLO

TR-250A



CERTIFICATIONS



VLASTNOSTI

- Easily fixes onto asymmetric DIN rail or mounts with screws
- Bolts included for output connections
- Transparent protection cover
- Easy accessibility for wiring
- Ready to use out of the box, saving installation time and labor
- RoHS compliant

VLASTNOSTI PRODUKTU

- Article Number: 563170
- Materiál: Copper; Glass Fibre Reinforced Polyamide; Plexiglass

Max Working Voltage, IEC (Ui): 630

Peak Short Circuit Current (Ipk): 34kA

Short Term Withstand Current (Icw) 1s: 17kA

Line Side Number of Connections: 2

Load Side Number of Connections: 4

Hole Size (HS): 8mm

Thread Size (TS): M6

Hloubka (D): 68mm

Height (H): 150mm

Width (W): 230mm

Unit Weight: 1.3kg


Flammability Rating: UL® 94V-0

Complies With: IEC® 60439.1; IEC® 61439.1; IEC® 60695-2-11 (Glow Wire Test 960 °C)

DALŠÍ PODROBNOSTI O PRODUKTU

Line side and load side number of connections are per pole.

DIAGRAMS

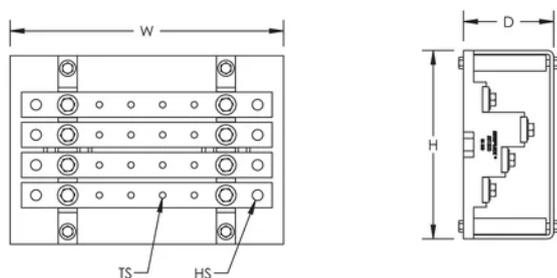

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE