 



MSP0 PDU, 3U, 100A(80A)NA/80A Int, 380-415V, 3P Wye, 12 CB, (18)C13, (18)4-in-1

Data Solutions

KATALOGOVÉ ČÍSLO

EN69HB

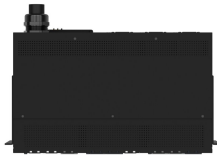

The Advantage Series Outlet Metered, Outlet Switched PDU family offers energy metering with advanced power and environmental monitoring options and remote outlet on/off switching. Comprehensive monitoring at the input phase, circuit breaker, and individual outlet levels offers advanced alerts of potential overloads. Billing-grade metering provides accurate power consumption data for energy use optimization. The hot-swappable network management controller features Gigabit and redundant ethernet communication with advanced support for external environmental sensors and rack security access solutions.

VLASTNOSTI

IEC 62368 listed. RoHS, and REACH compliant. See drawing for additional information.

UL 2900-1 certified for safety software cybersecurity for network-connectable products.

Dual network connectivity ports: 1x Gigabit Ethernet (10/100/1000 Mbps) and 1x (10/100 Mbps) connection/IP address

Ethernet cascading up to 64 PDUs

Each PDU can provide DC power sufficient to power network management electronics

Dual Ethernet ports for redundant network communications

Remote connectivity through HTTP(s), IPv4 and IPv6, SSH, Virtual Serial, SNMP (v1, v2c, v3), JSON-RPC, LDAP(S)

Data efficient REACT framework with native mobile device support

Tool-less hot swappable Network Management Card (NMC) with Cortex A-5 for microprocessing and memory that can be installed both upright and upside down for top or bottom power inputs

The border color of the NMC display is user programmable for power source identification by PDU

The NMC supports up to 10 digital sensors for environmental and/or electronic lock monitoring

Display languages include English, Spanish, German, French, Italian, Korean, Japanese, and Chinese (simplified)

VLASTNOSTI PRODUKTU

Produktová řada: Enlogic

Typ: Intelligent PDU

Product Type: Socket Strip

Typ zásuvky: (18) C13/C15; (18) C13/C15/C19/C21

Socket Quantity: 36

Barva: Black

Switched Outlets: Yes

Power Rating: 57.6 kVA North America; 55.2 kVA International

Cable Length: 1800mm

Circuit Breaker: 20 A, 1-pole, Hy-MagA

Circuit Breaker Quantity: 12

Nominální napětí: 415V

Nominal Power Output: 230VAC

Number of Output Voltages: 36

Amperage (Derated Amperage): 100 A (80 A) North America; 80 A International

Rack Units: 3U

On/Off Switch Included: Yes

Output Voltage: 208 – 230VAC

Metering Type: Outlet

Plug Type: IEC 60309 5125P6W (IP67)

Removable Input Cable: No

Materiál: Ocel

Povrchová úprava: Strukturovaný Práškový

Výška: 132mm

Šířka: 444mm

Hloubka: 269mm

Množství v balení: 1

Input Cable Length: 1.8m

DALŠÍ PODROBNOSTI O PRODUKTU

Warranty : nVent Enlogic branded equipment provided shall be free from manufacturing defects for a period of five (5) years from the invoice date to the original purchaser.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE