

Strut Seismic Hinge Bracket Assembly

Data Solutions



CERTIFICATIONS



VLASTNOSTI

Used for installations where strut brace is parallel to structure

One wrench size fits all required hardware, eliminating the need to change tools

Shear-off head helps ensure correct torque and simplifies inspection

SPECIFIKACE

Povrchová úprava: Electrogalvanized

 

Materiál: Ocel

Table 1/1

Katalogové číslo	Article Number	Hole Size (HS)	Width (W)	Thickness (T)	A	B
CSBUS2PA	404603	20.6mm	40.6mm	6.4mm	177.8mm	47.8mm
CSBUS1PA	404602	14.3mm	40.6mm	6.4mm	177.8mm	47.8mm

FM Loads					
Part Number	Brace Member	Horizontal Capacity per Installation Angle from Vertical			
		30° - 44°	45° - 59°	60° - 74°	75° - 90°
CSBUS1PA	41 x 41 Strut Channel	5160 N	8290 N	8290 N	7470 N
CSBUS2PA	41 x 41 Strut Channel	5160 N	8290 N	8290 N	7470 N

DIAGRAMS

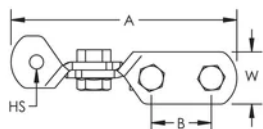

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE