


Countersunk Screw

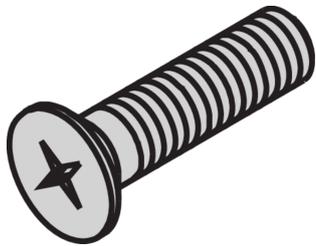

Countersunk screws are used for numerous mounting options in a subrack or desktop case.

CERTIFICATIONS



VLASTNOSTI

Countersunk screw

SPECIFIKACE

Product Type: Screw

Table 1/2

| Katalogové číslo | Length | Materiál | Povrchová úprava | Množství v balení | Thread Size | Výška |
|------------------|--------|----------|------------------|-------------------|-------------|-------|
| 24560-139 | 5mm | Ocel | Pozinkovaná Ocel | 100 | M4 | |
| 24560-183 | 12mm | Ocel | Pozinkovaná Ocel | 100 | M5 | |
| 24560-182 | 12mm | Ocel | Pozinkovaná Ocel | 4 | M5 | |
| 24560-145 | 14mm | Ocel | Pozinkovaná Ocel | 100 | M4 | |
| 24560-164 | 8mm | Ocel | Nickel Plated | 100 | M2.5 | 4.7mm |
| 24560-158 | 7.7mm | Ocel | Pozinkovaná Ocel | 100 | M2.5 | |

| Katalogové číslo | Length | Materiál | Povrchová úprava | Množství v balení | Thread Size | Výška |
|------------------|--------|----------|------------------|-------------------|-------------|-------|
| 21100-542 | 8mm | Ocel | Nickel Plated | 100 | M3 | |
| 21100-429 | 8mm | Ocel | Nickel Plated | 100 | M2.5 | |
| 21100-649 | 10mm | Ocel | Pozinkovaná Ocel | 100 | M2.5 | |
| 21100-500 | 10mm | Ocel | Nickel Plated | 100 | M2.5 | |
| 21100-507 | 12mm | Ocel | Nickel Plated | 100 | M2.5 | |

Table 2/2

| Katalogové číslo | Typ | Šířka | Works With | Thread Type | Torque |
|------------------|-------------------|-------|--------------|-------------|--------|
| 24560-139 | Countersunk Screw | | Front Panels | | 1.3N·m |
| 24560-183 | Countersunk Screw | | Front Panels | | 2.4N·m |
| 24560-182 | Countersunk Screw | | Front Panels | | 2.4N·m |
| 24560-145 | Countersunk Screw | | Front Panels | | 2.4N·m |
| 24560-164 | Countersunk Screw | 4.7mm | Front Panels | Metric | |
| 24560-158 | Countersunk Screw | | Front Panels | | |
| 21100-542 | Screw | | Front Panels | | |
| 21100-429 | Screw | | Front Panels | | |
| 21100-649 | Screw | | Front Panels | | |
| 21100-500 | Screw | | Front Panels | | |
| 21100-507 | Screw | | Front Panels | | |

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE