


MTCA.4 Cube System for 7 Double AMC Modules, 5 U, 42 HP

KATALOGOVÉ ČÍSLO

11850-021

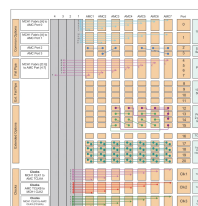

The system is designed for development and lab testing work. The hot-swap fan module with EMMC ensures that the front and rear slots are properly cooled at a low noise level. The fan speed is controlled independently for front and rear and is set via the MCH. The backplane features clock and trigger lines per PICMG MTCA.4, as well as interlocks. It also provides direct connections for SAS/SATA and lines between the AMCs.

CERTIFICATIONS



VLASTNOSTI

In accordance with PICMG MTCA.4 R1.0 specification

5 U, 42 HP cube system for 6 Double Mid-Size and 1 Double Full-Size AdvancedMC modules, 1 Double Full-Size MCH and 1 Double Full-Size power module

6 rear transition module slots for Double Mid-Size modules and one slot for Double Full-Size

Backplane with star topology, direct connections for S-ATA/SAS, clock and trigger lines per PICMG MTCA.4

Clock topology per PICMG AMC.0 R2.0

Hot-swap fan module with cooling unit manager (CU EMMC), airflow from bottom to top, fan speed for front and rear sections can be separately adjusted via MCH

Air filter accessible from the front

VLASTNOSTI PRODUKTU

Product Type: System

Number of Slots: 7

Typ: Half 19" Rack Mount

Backplane Type: MTCA.4 Star Topology

Data Transfer: 40 GbE; PCIe Gen3

Power per Slot: 80W

Airflow Direction: Bottom to Top

Rack Height: 5U

Power Supply Type: (1) Double Full-size PM

Power Supply Included: No

Rear I/O: Yes

Complies With: PICMG MTCA.4 R1.0

Hloubka: 373.3mm

Výška: 222.25mm

Net Weight: 10.35kg

Množství v balení: 1

DALŠÍ PODROBNOSTI O PRODUKTU

Modified systems available on request.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, použití, nesprávné použití nebo jiný nedostatek může vést k porušení záruky a výrobce nVent může zpochybnit

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE