


# Horizontal Rail Rear, Type AB for Rear I/O, With Notch, 84 HP

## KATALOGOVÉ ČÍSLO

**34579-040**

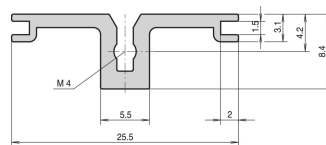

Combinations of horizontal rails and side panels

	„4“ can be combined	„3“ combination not recommended	„2“ combination not recommended	„1“ combination not recommended
Horizontal rail	-	+	+	+
Horizontal rail	+	+	+	+
Horizontal rail	+	+	-	-
Horizontal rail	+	+	-	-
Side panel	Light 1	Dark 2	Heavy 3	Rugged 4

*Note: „1“ can be combined*

Aluminum extrusion horizontal rail of the type AB (AB = support), for rear I/O card guides, with an anodized surface and conductive contact surface. Suitable for RatiopacPRO/-AIR and EuropacPRO/-rugged).

## VLASTNOSTI

For CompactPCI in the area of rear I/O

For 2 × 3 U expansion, 2 horizontal rails of type AB are required

Aluminum extrusion, anodized surface, conductive contact surface, without HP markings

## VLASTNOSTI PRODUKTU

Rack Width: 84HP

Množství v balení: 1

Povrchová úprava: Anodized

Length: 431.8mm

Materiál: Hliník

Produktová řada: EuropacPRO

Product Type: Horizontal Rail

Typ: Type AB

Works With: Subracks

Net Weight: 0.073kg

Rail Type: With Notch

## DALŠÍ PODROBNOSTI O PRODUKTU

---

Delivery is in standard pack multiples. Pricing is per individual item.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## UPOZORNĚNÍ

---

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na [www.nvent.com](http://www.nvent.com) a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Naše portfolio silných značek:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**