

# Plug-In Unit Front Panel for Static Trapezoid Handle



The front panel enables the assembly of a plastic or Alu-profile static trapezoid handle. The front panel cannot be shielded with a textile gasket.

## CERTIFICATIONS



## VLASTNOSTI

Front panel, unshielded

Front panel, Al, 2.5 mm, front anodized, conductive

## SPECIFIKACE

<b>Hloubka (D):</b>	2.5mm
<b>Materiál:</b>	Hliník
<b>Povrchová úprava:</b>	Anodized; Passivated
<b>Accessory Type:</b>	Front panel
<b>Product Type:</b>	Front Panel
<b>Typ:</b>	Front Panel for Handle (PIU)

Table 1/2

Katalogové číslo	Rack Height	Rack Width	Množství v balení	Typ rukojeti	Mounting	Front Finish
------------------	-------------	------------	-------------------	--------------	----------	--------------

30847-605	3U	6HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-604	3U	5HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-626	6U	4HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-627	6U	5HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-625	6U	3HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-628	6U	6HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-609	3U	12HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-629	6U	7HP	1	Trapezoid, Static	Screw-on Front	Anodized
30847-603	3U	4HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-608	3U	10HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-630	6U	8HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-607	3U	8HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized


30847-602	3U	3HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-631	6U	10HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-632	6U	12HP	1	Trapezoid, Static	Screw-on Front	Anodized
30847-606	3U	7HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized

Table 2/2

Katalogové číslo	Rear Finish	Treated Edges	Complies With	EMC Shielding	Výška (H)	Šířka (W)
30847-605	Conductive	No	IEC 60297-3-101	No	128.4mm	30.1mm
30847-604	Conductive	No	IEC 60297-3-101	No	128.4mm	25mm
30847-626	Conductive	No	IEC 60297-3-101	No	261.8mm	20mm
30847-627	Conductive	No	IEC 60297-3-101	No	261.8mm	25mm
30847-625	Conductive	No	IEC 60297-3-101	No	261.8mm	14.9mm
30847-628	Conductive	No	IEC 60297-3-101	No	261.8mm	30.1mm
30847-609	Conductive	No	IEC 60297-3-101	No	128.4mm	60.6mm
30847-629	Conductive	No	IEC 60297-3-101	No	261.8mm	35.2mm
30847-603	Conductive	No	IEC 60297-3-101	No	128.4mm	20mm
30847-608	Conductive	No	IEC 60297-3-101	No	128.4mm	50.5mm
30847-630	Conductive	No	IEC 60297-3-101	No	261.8mm	40.3mm
30847-607	Conductive	No	IEC 60297-3-101	No	128.4mm	40.3mm
30847-602	Conductive	No	IEC 60297-3-101	No	128.4mm	14.9mm

Katalogové číslo	Rear Finish	Treated Edges	Complies With	EMC Shielding	Výška (H)	Šířka (W)
30847-631	Conductive	No	IEC 60297-3-101	No	261.8mm	50.5mm
30847-632	Conductive	No	IEC 60297-3-101	No	261.8mm	60.6mm
30847-606	Conductive	No	IEC 60297-3-101	No	128.4mm	35.2mm

## DIAGRAMS

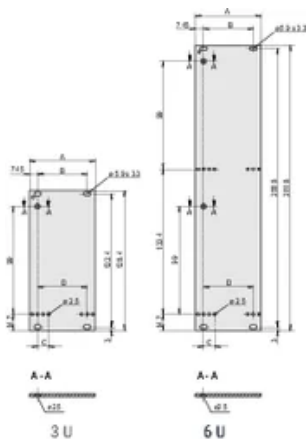

## UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na [www.nvent.com](http://www.nvent.com) a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Naše portfolio silných značek:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**