

EBC Beam Clamp



CERTIFICERINGER



FUNKTIONER

Easy installation to beam flanges

One 10.5mm go-through hole allows the use of M6, M8 or M10 threaded rod, to attach any static load till 450N

Featuring three M6 threaded holes to attach electrical boxes directly to the side or bottom of the beam

SPECIFIKATIONER

Finish: nVent CADDY Armour

Materiale: Spring Steel


Table 1/1

Katalognummer	Artikelnummer	Rod Size (RS)	Hole Size (HS)	Flange Thickness (FT)	Torque (TQ)	Static Load
EBC	170380	6	10.5 mm	16 mm Max	3 N·m	450N
EBCSP25	172430	6	10.5 mm	16 mm Max	3 N·m	450N

YDERLIGERE PRODUKTOPLYSNINGER

Setscrew must be tightened and torqued onto the sloped side of the I-beam.

DIAGRAMS

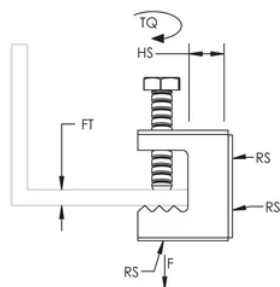

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

