

# nVent CADDY Macrofix Plus Kombi with Combination Nut, M8,M10,1/2"Rod, 37-44mm OD

## KATALOGNUMMER

---

**MPK044**



## FUNKTIONER

---

Includes easy closing mechanism

Age-resistant lining

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

## PRODUKTEGENSKABER

---

Artikelnummer: 586756

Rod Size (RS): M8;M10;1/2"

Temperature: -50 to 110 °C

Farve: Black

Materiale: Stål;EPDM-SBR Rubber

Finish: Electrogalvanized

Outer Diameter (OD): 37 - 44 mm

Pipe Size: 1 1/4" Min

NB/DN: 32

Width (W): 20 mm

Thickness (T): 1 mm

Screw Diameter (Sc): 6 mm

Screw Length (L): 37mm


Static Load: 1000N

Unit Weight: 0.12 kg

## YDERLIGERE PRODUKTOPLYSNINGER

Lining is EPDM rubber.

## DIAGRAMS

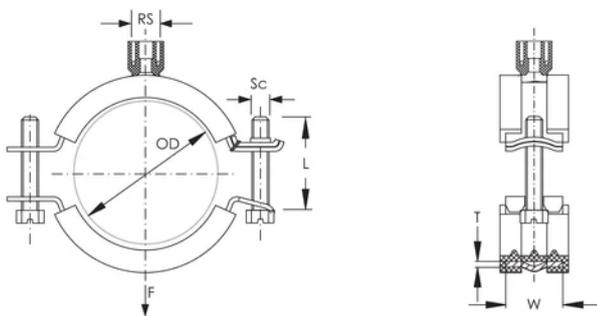

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unndladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

