

Heavy Duty Pipe Clamp, Painted, Red Oxide, 40–43 mm OD, 1 1/4" Pipe, 32 DN

KATALOGNUMMER

SSG043RO



FUNKTIONER

For high static requirements in industrial construction

Suitable for fix point applications

PRODUKTEGENSKABER

Artikelnummer: 574630

Materiale: Stål

Finish: Painted;Red Oxide

Outer Diameter (OD): 40 - 43 mm

Pipe Size: 1 1/4" Min

NB/DN: 32

Hole Size (HS): 11 mm

Screw Diameter (Sc): 10 mm

Screw Length (L): 40mm

Static Load: 1000N

Width (W): 40 mm


Thickness (T): 4 mm

A: 79 mm

YDERLIGERE PRODUKTOPLYSNINGER

Static load refers to a complete set of Heavy Duty Pipe Clamps held in place with indicated screws per ISO 4014 and corresponding hex nuts per ISO 4032 (for further information, please refer to Standard SSG 7075E).

DIAGRAMS

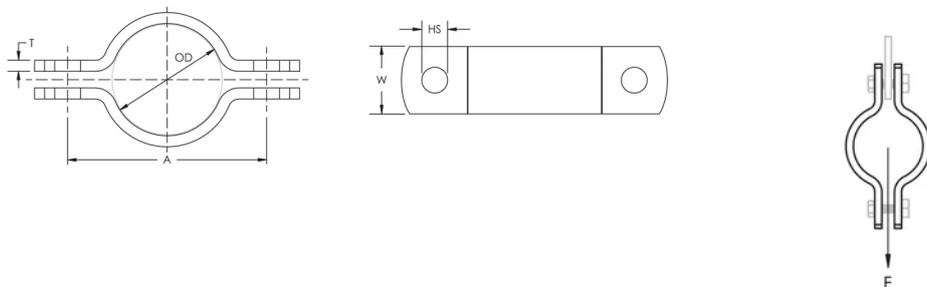

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unndladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

