

# nVent CADDY Superfix 243 M8/M10, 15–19 mm OD, 3/8" Pipe, 10 DN

## KATALOGNUMMER

---

**SXD019**



## CERTIFICERINGER

---



## FUNKTIONER

---

Includes easy closing mechanism

Combo head bolt works with slotted, hex, or Phillips drivers

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

## PRODUKTEGENSKABER

---

Artikelnummer: 400064

Materiale: Stål;EPDM-SBR Rubber

Finish: Electro galvanized

Farve: Black

Temperature: -50 to 110 °C

Outer Diameter (OD): 15 - 19 mm

Pipe Size: 3/8"

NB/DN: 10

Rod Size (RS): M8;M10

Width (W): 20 mm

Thickness (T): 1.2 mm

Screw Diameter (Sc): 5

Screw Length (L): 25mm

Static Load: 1000N


## YDERLIGERE PRODUKTOPLYSNINGER

---

Lining is EPDM rubber.

## DIAGRAMS

---

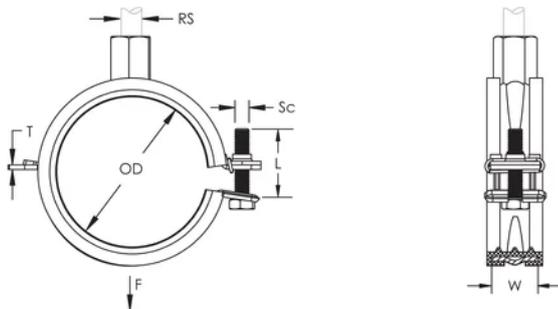

## ADVARSEL

---

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

**North America**

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

**Europe**

Netherlands:

+31 800-0200135

France:

+33 800 901 793

**Europe**

Germany:

800 1890272

Other Countries:

+31 13 5835404

**APAC**

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

