

# nVent CADDY Superfix 243 M8/M10, 108–114 mm OD, 4" Pipe, 100 DN

## KATALOGNUMMER

**SXD114**



## CERTIFICERINGER



## FUNKTIONER

Includes easy closing mechanism

Combo head bolt works with slotted, hex, or Phillips drivers

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

## PRODUKTEGENSKABER

Artikelnummer: 400077

Materiale: Stål;EPDM-SBR Rubber

Finish: Electrogalvanized

Farve: Black

Temperature: -50 to 110 °C

Outer Diameter (OD): 108 - 114 mm

Pipe Size: 4"

NB/DN: 100

Rod Size (RS): M8;M10

Width (W): 23 mm

Thickness (T): 2 mm

Screw Diameter (Sc): 6


Screw Length (L): 35mm

Static Load: 2200N

## YDERLIGERE PRODUKTOPLYSNINGER

Lining is EPDM rubber.

## DIAGRAMS

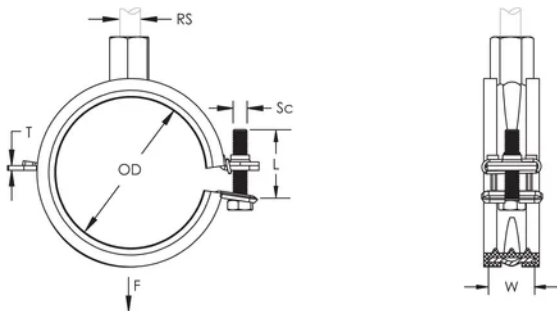

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

