


MTVB Gravity Toggle with Rubber Washer

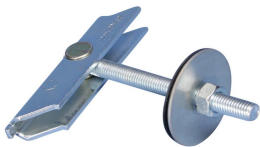

CERTIFICERINGER



FUNKTIONER

Complete with rod, nut, washer and load distribution block

Threaded rod is secured against unintentional removal

Approved for use in stationary fire protection systems (for pipes up to 2")

SPECIFIKATIONER

Finish: Electrogalvanized

Materiale: Stål

Table 1/2

Katalognummer	Artikelnummer	Rod Size (RS)	Length (L)	Drill Bit Diameter	Static Load	Ultimate Static Load (F)
MTVB10100	584465	10	100mm	25mm	800N	20kN
MTVB8100	584455	8	100mm	22mm	800N	20kN
MTVB8200	584456	8	200mm	22mm	800N	20kN
MTVB10200	584466	10	200mm	25mm	800N	20kN

Table 2/2


Katalognummer	Artikelnummer	Certificeringer
MTVB10100	584465	FM Approved, Pipe Hanger Components, VdS G412037
MTVB8100	584455	VdS G412037
MTVB8200	584456	VdS G412037
MTVB10200	584466	FM Approved, Pipe Hanger Components

YDERLIGERE PRODUKTOPLYSNINGER

Static Load represents the maximum recommended load when fixed to a trapezoidal sheet.

The Ultimate Static Load value does not take into account the load-bearing characteristics of the supporting material. The appropriate safety factor is to be added to this load rating.

DIAGRAMS

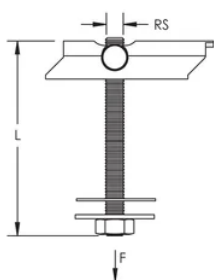

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

