

# Pipe/Cable Clamp



## FUNKTIONER

Captive threaded stud minimizes the need for additional hardware

With the UNICBAND Sign Support Bracket and Fixoband Strap, attachments to pipe and pole can be made

## SPECIFIKATIONER

Table 1/2


Katalognummer	Artikelnummer	Materiale	Finish	NB/DN	Outer Diameter (OD)	Width (W)
CR037HD	336300	Stål	Hot-Dip Galvanized	10	16 - 20 mm	16 mm
CR037S4	336400	Stainless Steel 304 (EN 1.4301)		10	16 - 20 mm	16 mm
CR050HD	336310	Stål	Hot-Dip Galvanized	15	20 - 25 mm	16 mm
CR050S4	336410	Stainless Steel 304 (EN 1.4301)		15	20 - 25 mm	16 mm
CR075HD	336320	Stål	Hot-Dip Galvanized	20	26.9 - 31.8 mm	16 mm
CR075S4	336420	Stainless Steel 304 (EN 1.4301)		20	26.9 - 31.8 mm	16 mm
CR087HD	336322	Stål	Hot-Dip Galvanized		32 - 34 mm	16 mm

Katalognummer	Artikelnummer	Materiale	Finish	NB/DN	Outer Diameter (OD)	Width (W)
CR150S4	336450	Stainless Steel 304 (EN 1.4301)		40	47 - 51 mm	20 mm
CR200S4	336460	Stainless Steel 304 (EN 1.4301)		50	59.2 - 63.5 mm	20 mm
CR125S4	336440	Stainless Steel 304 (EN 1.4301)		32	40.0 - 44.5 mm	20 mm
CR200HD	336360	Stål	Hot-Dip Galvanized	50	59.2 - 63.5 mm	20 mm
CR125HD	336340	Stål	Hot-Dip Galvanized	32	40.0 - 44.5 mm	20 mm
CR100HD	336330	Stål	Hot-Dip Galvanized	25	33.7 - 38 mm	20 mm
CR100S4	336430	Stainless Steel 304 (EN 1.4301)		25	33.7 - 38 mm	20 mm
CR150HD	336350	Stål	Hot-Dip Galvanized	40	47 - 51 mm	20 mm

Table 2/2

Katalognummer	Artikelnummer	Static Load 1 (F1)	Static Load 2 (F2)
CR037HD	336300	125N	550N
CR037S4	336400	125N	550N
CR050HD	336310	125N	550N
CR050S4	336410	125N	550N
CR075HD	336320	125N	550N
CR075S4	336420	125N	550N
CR087HD	336322	125N	550N
CR150S4	336450	250N	550N
CR200S4	336460	250N	550N
CR125S4	336440	250N	550N
CR200HD	336360	250N	550N
CR125HD	336340	250N	550N
CR100HD	336330	250N	550N
CR100S4	336430	250N	550N
CR150HD	336350	250N	550N

## DIAGRAMS

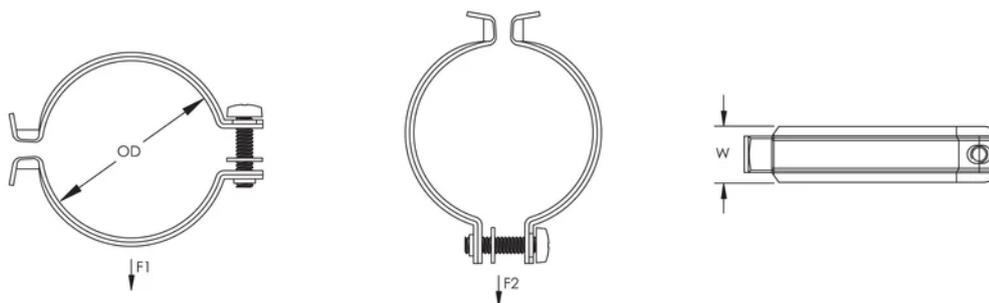

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unkladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

