

Telescoping Strut Replacement, No Nut



FUNKTIONER

Can be attached directly to a wall for wall-mounted applications

Telescopes to the desired length and is locked in place by snapping closed a spring retainer clip

Standard strut profile runs the entire length of the part, allowing most standard fittings to be placed anywhere between the rods

Integrated ruler displays space between hanger rods in inches and centimeters

Supports up to seven 2" (50 DN) conduits, six 2" (50 DN) water filled pipes at 10' (3 m) spacing, or up to 18" (450 mm) cable tray

Conduit can be supported on the top and bottom, eliminating the need for double sided strut

Conduit and pipe can be placed directly on the strut profile, saving vertical space in buildings with limited room for installation

SPECIFIKATIONER

Table 1/3

Katalognummer	Artikelnummer	Materiale	Finish	Hole Size 1 (HS1)	Hole Size 2 (HS2)	Thickness (T)
TSR1220N	366593	Stål	Pregalvanized	13.7 mm	4.8 mm	1 mm

Table 2/3

Katalognummer	Artikelnummer	A	B	C	D	E
TSR1220N	366593	318 - 508 mm	356 - 546 mm	41 mm	22.2 mm	35 mm

Table 3/3


Katalognummer	Artikelnummer	Static Load 1 (F1)	Static Load 2 (F2)
---------------	---------------	--------------------	--------------------

TSR1220N	366593	1330N	880N
----------	--------	-------	------

YDERLIGERE PRODUKTOPLYSNINGER

Static Load 1 represents a distributed load for 12" - 20" (300 - 500 mm) installations and a point load for 12" - 16" (300 - 400 mm) installations. Static Load 2 represents a point load for 16" - 20" (400 - 500 mm) installations.

DIAGRAMS

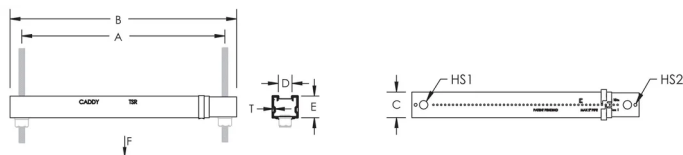

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

