

# 19" Front Panel, Vented

## Data Solutions

Vented front panels allows heat dissipation through holes.



### CERTIFICERINGER



### FUNKTIONER

Vented front panels (Aluminium ) allows heat dissipation

### SPECIFIKATIONER

- Rack Width:** 95HP
- Materiale:** Aluminium
- Accessory Type:** Front panel
- Product Type:** Front Panel

Table 1/2

Katalognummer	Rack Height	Finish	Mounting	Pakke mængde	Front Finish	Rear Finish
30118-962	1U	Struktur Pulvermaling	Screw-on Front	1	Painted	Painted
30702-047	1U	Anodized	Screw-on Front	1	Anodized	Anodized

Katalognummer	Rack Height	Finish	Mounting	Pakke mængde	Front Finish	Rear Finish
30702-056	1U	Struktur Pulvermaling	Screw-on Front	1	Painted	Painted
30702-044	1U	Anodized	Screw-on Front	1	Raw	Conductive
30118-963	2U	Anodized	Screw-on Front	1	Painted	Painted
30702-048	2U	Anodized	Screw-on Front	1	Anodized	Anodized
30702-057	2U	Struktur Pulvermaling	Screw-on Front	1	Painted	Painted
30118-964	3U	Struktur Pulvermaling	Screw-on Front	1	Painted	Painted
30702-058	3U	Struktur Pulvermaling	Screw-on Front	1	Painted	Painted
30702-046	3U	Anodized	Screw-on Front	1	Raw	Raw
30702-045	2U	Anodized	Screw-on Front	1	Raw	Raw
30702-049	3U	Anodized	Screw-on Front	1	Anodized	Anodized

Table 2/2


Katalognummer	Treated Edges	Farvekode	EMC Shielding	Højde (H)	Type	Bredde (W)
30118-962		RAL 7021	No	43.6mm	19" Front Panel	483mm
30702-047	Yes		No	43.6mm	19" Front Panel	483mm
30702-056		RAL 7035	No	43.6mm	19" Front Panel	483mm
30702-044			No	43.6mm	19" Front Panel	483mm
30118-963		RAL 7021	No	88.1mm	19" Front Panel	483mm
30702-048	Yes		No	88.1mm	19" Front Panel	483mm
30702-057		RAL 7035	No	88.1mm	19" Front Panel	483mm
30118-964		RAL 7021	No	132.5mm	19" Front Panel	483mm
30702-058		RAL 7035	No	132.5mm	19" Front Panel	483mm
30702-046			No	132.5mm	19" Front Panel	483mm
30702-045			No	88.1mm	19" Front Panel	483mm
30702-049	Yes		No	132.5mm	19" Front Panel	483mm

## YDERLIGERE PRODUKTOPLYSNINGER

Please order 19" assembly kit separately.

## DIAGRAMS

---

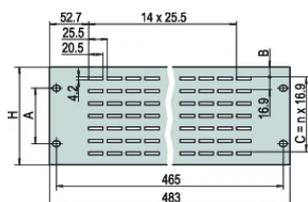

## ADVARSEL

---

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**