

# Branch Line Restraint Pipe Attachment

## Data Solutions



### CERTIFICERINGER



### FUNKTIONER

Accepts 3/8" or 1/2" (M10 or M12) threaded rod

Quick grip clamp simplifies measuring and cutting of threaded rod

Eliminates need to cut threaded rod to exact dimensions

Works with rough-cut threaded rod and eliminates pipe-side deburring

Can be installed with threaded rod above or below the service pipe

Shear-off head helps ensure correct torque and simplifies inspection

### SPECIFIKATIONER

**Finish:** Electrogalvanized

**Materiale:** Stål

Table 1/2


Katalognummer	Artikelnummer	NB/DN	Outer Diameter (OD)	Rod Size (RS)	Height (H)	Length (L)
---------------	---------------	-------	---------------------	---------------	------------	------------

CSBBRP0200EG	404480	50	60.3mm	10, 12	100.3mm	68.3mm
CSBBRP0125EG	404478	32	42.2mm	10, 12	82.6mm	50mm
CSBBRP0100EG	404477	25	33.4mm	10, 12	73.7mm	41.4mm
CSBBRP0150EG	404479	40	48.3mm	10, 12	88.9mm	56.1mm

Table 2/2

Katalognummer	Artikelnummer	Width (W)
CSBBRP0200EG	404480	22.2mm
CSBBRP0125EG	404478	22.2mm
CSBBRP0100EG	404477	22.2mm
CSBBRP0150EG	404479	22.2mm

## DIAGRAMS

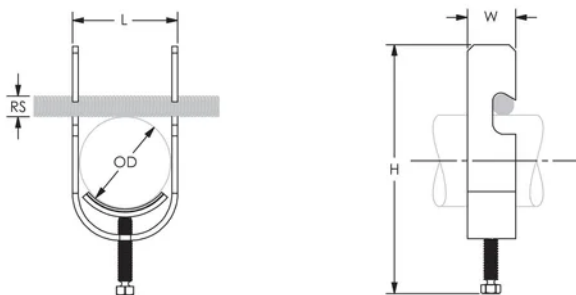

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**