


Two Pole Distribution Block, 80/100 A, 1 Line Side & 6 Load Side Connections

Data Solutions

KATALOGNUMMER

BD-80-100A

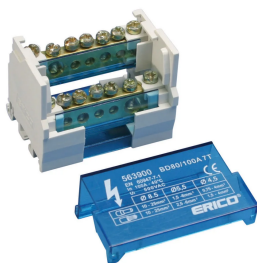

CERTIFICERINGER



FUNKTIONER

Minimum space for maximum power

Protection cover and insulating screens are transparent

Insulating screen between each row

Easy and safe connections

Wiring with or without terminal

Easily clips onto DIN rail or mounts to panel with screws

RoHS compliant

Conforms to EN 45545 obtaining an HL3 classification for chapter R23 and HL2 classification for chapter R22

Halogen free

PRODUKTEGENSKABER


Artikelnummer: 563900
Max Current Rating, IEC: 100A
Short Term Withstand Current (Icw) 1s: 4.5kA
Peak Short Circuit Current (Ipk): 20kA
Max Working Voltage, IEC (Ui): 500V
Line Side Number of Connections: 1
Line Side Compact Stranded Wire Size: 10 - 25 mm²
Line Side Stranded Wire Size - Ferrule: 10 – 25mm²
Load Side Number of Connections: 6
Load Side Compact Stranded Wire Size: (3) 1,5 - 4 mm²; (3) 2,5 - 6 mm²
Load Side Stranded Wire Size - Ferrule: (3) 0,75 – 4 mm²; (3) 1,5 – 6 mm²
Dybde (D): 50mm
Height (H): 50mm
Width (W): 64mm
Unit Weight: 0.11kg
Flammability Rating: UL® 94V-0
Complies With: IEC® 60947-7-1

YDERLIGERE PRODUKTOPLYSNINGER

Line side and load side number of connections are per pole.

Design Guideline for Distribution Blocks, Power Blocks and Power Terminals										
Derating according to Ambient* Temperature (°C) to maintain working temperature of 85°C										
Ambient Temperature (°C)	30°	35°	40°	45°	50°	55°	60°	65°	70°	75°
Derating Coefficient (d)	1	1	1	0.94	0.88	0.82	0.75	0.67	0.58	0.47
*environment around the terminal blocks inside the enclosure										

DIAGRAMS

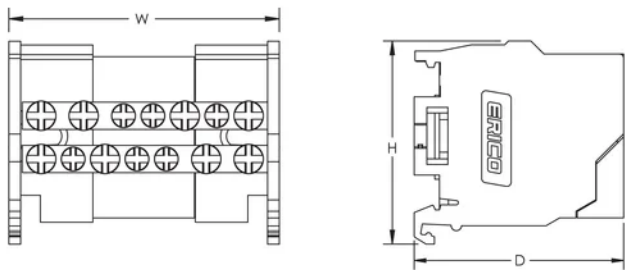

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE