

# Cat HP J-hook, pre-galvanized, 25 mm diameter

## Data Solutions

### KATALOGNUMMER

### CAT16HP



nVent CADDY Cat HP J-Hooks are the foundation of the nVent CADDY Cat HP System. The revamped nVent CADDY Cat HP J-Hook offers contractors three unique, UL-certified attachment methods out of the box—wall, ceiling, and threaded rod installations. This added functionality enables contractors to reduce SKU inventory while maintaining efficiency and continued progress on the jobsite with the most common structural attachment methods.

The modernized design of the nVent CADDY Cat HP J-Hook is engineered to provide optimal support and protection for today's rapidly evolving, high-performing low voltage cable. Contractors can feel confident utilizing the nVent CADDY Cat HP J-Hook due to its installation versatility, superior cable support and protection, and technical certifications.

### CERTIFICERINGER



### FUNKTIONER

Versa-Mount Technology: Innovative attachment design provides multiple structural and installation methods for wall, ceiling, and threaded rod mounting applications

Ideal for unknown jobsite applications or attachment methods

Improved design allows for optimized inventory while reducing job site scheduling risks associated with multiple SKUs

Provides optimal support for high-performance data cable—including category cable, Power over Ethernet (PoE), and fiber optic

Industry-leading bend radius designed to protect high-performance data installations

Multiple color options aid in the identification and organization of the pathway application

Provides superior fill capacity and load rating

Compliant with UL® 2043 and suitable for use in air handling (plenum) spaces

Meets ISO®/IEC 14763-2, ANSI®/TIA 568 and ANSI®/TIA 569

Complies with EN 50174-2

## PRODUKTEGENSKABER

---

Artikelnummer: 181061

Materiale: Stål

Finish: Pregalvanized

Diameter (Ø): 25mm

Area: 690mm<sup>2</sup>

Cable Capacity, Cat 5e: 20

Cable Capacity, Cat 6: 15

Cable Capacity, Cat 6A: 10

Height 1 (H1): 108.9mm

Height 2 (H2): 90.2mm

Static Load: 267N

## YDERLIGERE PRODUKTOPLYSNINGER

---


Non-continuous supports may not exceed spacing of 5' (1.5 m) per TIA 569-C.9.7 and EN 50174-2.

Cable capacity is calculated based on a 70% fill rate.

| Fire Rated Power Cable Capacity (Distance between J-hooks must not exceed 500 mm center to center) |                                   |                  |                |                  |                |                  |             |                  |             |
|----------------------------------------------------------------------------------------------------|-----------------------------------|------------------|----------------|------------------|----------------|------------------|-------------|------------------|-------------|
| Part Number                                                                                        |                                   | CAT16HP          |                | CAT32HP CAT48HP  |                | CAT64HP          |             | CAT64HP          |             |
| Configuration                                                                                      |                                   | Single Layer     |                | Single Layer     |                | Single Layer     |             | Double Layer     |             |
| Max Load per Support [kg/m]                                                                        |                                   | 0.8 kg/m         |                | 1.4 kg/m         |                | 2.6 kg/m         |             | 2 kg/m           |             |
| Cable                                                                                              | Linear Weight of the Cable [kg/m] | Number of Cables | Classification | Number of Cables | Classification | Number of Cables |             | Classification n |             |
| 4x1,5 (N)HXH FE180 E30-E60                                                                         | 0.234                             | 3                | E30            | 5                | E30 E60        | 11               | E30 E60     | 8                | E30 E60     |
| 5x1,5 (N)HXH FE180 E30-E60                                                                         | 0.277                             | 2                |                | 5                | E30            | 9                | E30         | 7                | E30         |
| 7x1,5 (N)HXH FE180 E30-E60                                                                         | 0.330                             | 2                |                | 4                |                | 7                |             | 6                |             |
| 12x1,5 (N)HXH FE180 E30-E60                                                                        | 0.513                             | 1                |                | 2                |                | 5                |             | 3                |             |
| 19x1,5 (N)HXH FE180 E30-E60                                                                        | 0.715                             | 1                |                | 1                |                | 3                |             | 2                |             |
| 24x1,5 (N)HXH FE180 E30-E60                                                                        | 0.901                             | -                |                | 1                |                | 2                |             | 2                |             |
| 30x1,5 (N)HXH FE180 E30-E60                                                                        | 1.052                             | -                |                | 1                |                | 2                |             | 1                |             |
| 2x2,5 (N)HXH FE180 E30-E60                                                                         | 0.178                             | 4                | E30            | -                |                | -                |             | -                |             |
| 3x2,5 (N)HXH FE180 E30-E60                                                                         | 0.250                             | 3                |                | -                |                | -                |             | -                |             |
| 4x2,5 (N)HXH FE180 E30-E60                                                                         | 0.296                             | 2                |                | -                |                | -                |             | -                |             |
| 5x2,5 (N)HXH FE180 E30-E60                                                                         | 0.352                             | 2                |                | -                |                | -                |             | -                |             |
| 4x1,5 (N)HXH FE180 E90                                                                             | 0.234                             | 3                | E30 E60 E90    | 5                | E30 E60 E90    | 11               | E30 E60 E90 | 8                | E30 E60 E90 |
| 5x1,5 (N)HXH FE180 E90                                                                             | 0.277                             | 2                |                | 5                |                | 9                |             | 7                |             |
| 7x1,5 (N)HXH FE180 E90                                                                             | 0.330                             | 2                |                | 4                |                | 7                |             | 6                |             |
| 12x1,5 (N)HXH FE180 E90                                                                            | 0.511                             | 1                |                | 2                |                | 5                |             | 3                |             |
| 24x1,5 (N)HXH FE180 E90                                                                            | 0.901                             | -                |                | 1                |                | 2                |             | 2                |             |
| 2x2x0,8 JE-H(St)H...Bd FE180 E30-E90                                                               | 0.060                             | 13               | E30            | -                |                | -                |             | -                |             |
| 4x2x0,8 JE-H(St)H...Bd FE180 E30-E90                                                               | 0.102                             | 7                |                | -                |                | -                |             | -                |             |
| 8x2x0,8 JE-H(St)H...Bd FE180 E30-E90                                                               | 0.221                             | 3                |                | -                |                | -                |             | -                |             |
| 12x2x0,8 JE-H(St)H...Bd FE180 E30-E90                                                              | 0.281                             | 2                |                | -                |                | -                |             | -                |             |
| 16x2x0,8 JE-H(St)H...Bd FE180 E30-E90                                                              | 0.326                             | 2                |                | -                |                | -                |             | -                |             |
| 20x2x0,8 JE-H(St)H...Bd FE180 E30-E90                                                              | 0.421                             | 1                |                | -                |                | -                |             | -                |             |

|                                                                                             |       |                                                                   |               |              |               |
|---------------------------------------------------------------------------------------------|-------|-------------------------------------------------------------------|---------------|--------------|---------------|
| 32x2x0,8 JE-H(St)H...Bd<br>FE180 E30-E90                                                    | 0.588 | 1                                                                 | -             | -            | -             |
| 40x2x0,8 JE-H(St)H...Bd<br>FE180 E30-E90                                                    | 0.761 | 1                                                                 | -             | -            | -             |
| <b>Fire rating applicable when linking specified J-hook<br/>to the following components</b> |       | <b>Fire rating applicable to the following riveted assemblies</b> |               |              |               |
| <b>Part number</b>                                                                          |       | <b>Part number</b>                                                |               |              |               |
| CATHPAN                                                                                     |       | CAT16HPAB                                                         | CAT32HPAB     | CAT48HPAB    | CAT64HPAB     |
| CATHPA4                                                                                     |       | CAT16HPBCB                                                        | CAT32HPAFAB3  | CAT48HPAFAB3 | CAT64HPAFAB3  |
| CATHPA6                                                                                     |       | CAT16HPBC200B                                                     | CAT32HPAFAB4  | CAT48HPAFAB4 | CAT64HPAFAB4  |
| CATHPMTM                                                                                    |       | CAT16HP24SM                                                       | CAT32HPAFAB6  | CAT48HPBCB   | CAT64HPBCB    |
| CATHPBCB                                                                                    |       | CAT16HP58SM                                                       | CAT32HPBCB    | CAT48HP58SM  | CAT64HPBC200B |
| CATHPBC200B                                                                                 |       | CAT16HP912SM                                                      | CAT32HPBC200B | CAT48HP912SM | CAT64HP58SM   |
| CATHP912SM                                                                                  |       | CAT16HP24                                                         | CAT32HP24SM   | CAT48HP24    | CAT64HP912SM  |
| CATHP24                                                                                     |       | CAT16HP58                                                         | CAT32HP912SM  | CAT48HP58    | CAT64HP24     |
| CATHP58                                                                                     |       | -                                                                 | CAT32HP24     | -            | -             |
| CATHP912                                                                                    |       | -                                                                 | -             | -            | -             |

## DIAGRAMS

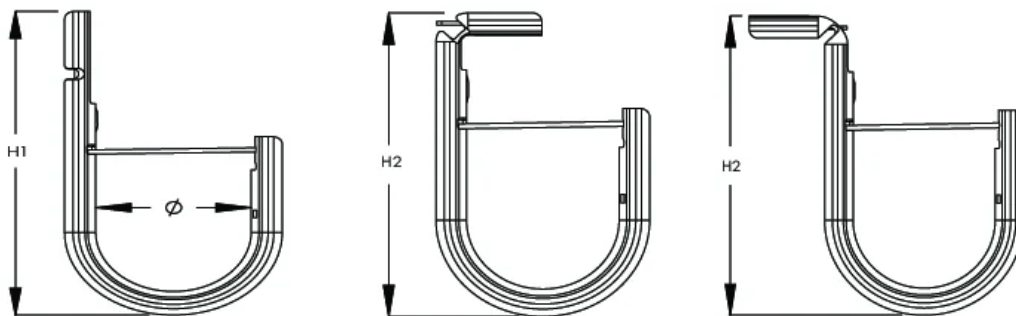

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**