

# Low Voltage Insulators, Metric Thread, 30 mm, 30 mm Hex Width, M6 Thread

## Data Solutions

### KATALOGNUMMER

**ISOTP30M6**



### CERTIFICERINGER



### FUNKTIONER

Halogen free

High resistance to leakage current

Great stability of electrical and mechanical parameters

Fiberglass reinforced

UL® Recognized in E125470 and evaluated for dielectric withstand rating of 1,500 VAC/DC

RoHS compliant

### PRODUKTEGENSKABER

Artikelnummer: 548440

Materiale: Stål; Glass Fibre Reinforced Polyamide

Finish: Electrogalvanized

Working Temperature: -40 to 130°C

Flammability Rating: UL® 94V-0

Complies With: IEC® 60695-2-11 (Glow Wire Test 960 °C)

Dielectric Strength, IEC 61439.1: 3500 VAC @ 1 min

Dielectric Strength, UL: 1500

Insulation Voltage: 1000; 1500

Height (H): 30mm

Hex Width (W): 30mm

Dybde (D): 34mm

Thread Size (TS): M6

Thread Depth (TD): 8mm

Diameter (Ø): 26mm

Static Load 1 (F1): 600daN


Static Load 2 (F2): 300daN

Unit Weight: 0.03kg

## YDERLIGERE PRODUKTOPLYSNINGER

Creepage and clearance distances need to be in accordance with the relevant application standard.

## DIAGRAMS

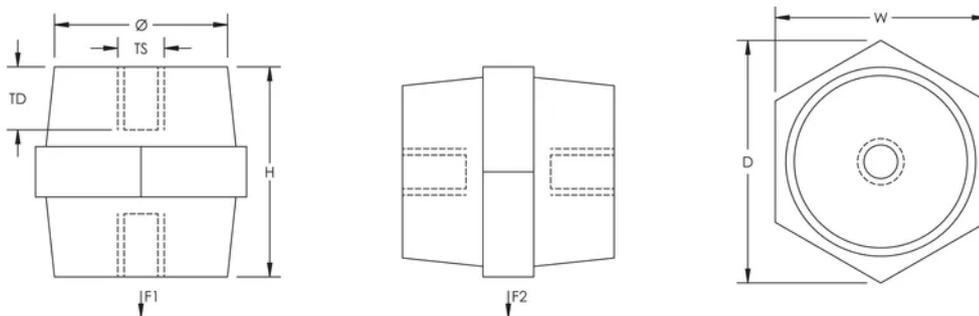

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**