

# Neutral Bar for TD Distribution Blocks, 125 A IEC

## Data Solutions

### KATALOGNUMMER

---

**NB-125A**



### CERTIFICERINGER

---



### FUNKTIONER

---

Attaches to four pole distribution blocks for increased wire capacity

Direct electrical connection

Strong mechanical assembly

Transparent protection cover

Halogen free

RoHS compliant

Conforms to EN 45545 obtaining an HL3 classification for chapter R23 and HL2 classification for chapter R22

### PRODUKTEGENSKABER

---

Artikelnummer: 563841

Max Current Rating, IEC: 125A

Short Term Withstand Current (Icw) 1s: 4.5kA

Peak Short Circuit Current (Ipk): 30kA

Line Side Number of Connections: 3

Line Side Compact Stranded Wire Size: 10 - 25 mm<sup>2</sup>

Line Side Stranded Wire Size - Ferrule: 6 – 16mm<sup>2</sup>

Load Side Number of Connections: 9

Load Side Compact Stranded Wire Size: 2,5 - 6 mm<sup>2</sup>

Load Side Stranded Wire Size - Ferrule: 1,5 – 6 mm<sup>2</sup>

Dybde (D): 37.4mm

Height (H): 34.3mm

Width (W): 142mm

Unit Weight: 0.17kg


For Use With: TD-100-125AL (563830); TD-100-125ALL (563840)

Flammability Rating: UL® 94V-0

Complies With: IEC® 60947-7-1

## DIAGRAMS

---

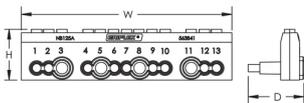

## ADVARSEL

---

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**