

Flat Braided Power Shunt, 100 mm², 500 mm

Data Solutions

KATALOGNUMMER

PBC100X500



CERTIFICERINGER



FUNKTIONER

Ideal for transformer-busduct link

Solid palms can be drilled to fit customer specific designs

Extra flexible power connection and good resistance to vibration

PRODUKTEGENSKABER

Artikelnummer: 564050

Materiale: Copper

Finish: Tinned

Wire Diameter: 0.15mm

Cross Section: 100mm²

ΔT 30 K: 349A

ΔT 50 K: 462A

Length (L): 500mm

A: 35mm

B: 40mm

C: 7mm


2 Bar Current Coefficient: 1.72

Unit Weight: 0.63kg

YDERLIGERE PRODUKTOPLYSNINGER

When used in parallel, the two shunts must be spaced with a minimum distance equal to the thickness of the shunt to allow air cooling.

DIAGRAMS

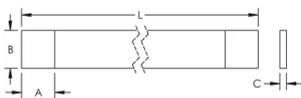

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE