


Joint Bond T6 Complete Welder Pair, Signal, Head Free Bond Terminal Style, 3/16" Bondstrand

Data Solutions

KATALOGNUMMER

SBHFT6C

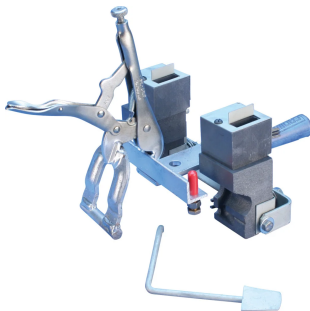

FUNKTIONER

Complete welder assembly provides a convenient means of attaching jumper bonds to the head of the rail, across the joint

Connection is made within the confines of the splice bar

Includes mold cleaner

PRODUKTEGENSKABER

Materiale: Stål; Graphite; Thermoplastic

Rail Type: 85 lb to 141 lb T-Rail Sections

Bond Terminal Style: Head Free

Conductor Size: 3/16" Bondstrand

Conductor Outer Diameter, Nominal: 4.76mm

Bond Length: 190.5mm

Welder Style: T6

Mold Only: No

Replacement Mold: SBS925M

Welding Material: SB32, Sold Separately

Frame: SBS925F, Sold Separately

Bond Clip: S2659 x 2, Sold Separately

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE