

Power Terminal, Lug-to-Lug, 800 A

Data Solutions

KATALOGNUMMER

SBLL-800



CERTIFICERINGER



FUNKTIONER

Tinned copper block allows for copper or aluminum conductor connections

Accessible studs allow for easy connection of sections of nVent ERIFLEX Flexibar or other conductors

Design allows for visual inspection of conductor and confirmation of connection

Adjustable transparent cover

Modular snap-together blocks for building multi-pole power blocks

Easily clips onto DIN rail or mounts to panel with screws

SBLEC Power Terminals Fixing Accessory required for direct panel mount

RoHS compliant

Halogen free

PRODUKTEGENSKABER


Artikelnummer: 561136
Materiale: Copper; Thermoplastic
Finish: Tinned
Max Current Rating, IEC: 1250A
Max Current Rating, UL/CSA: 800A
Short Term Withstand Current (Icw) 1s: 57.6kA
Peak Short Circuit Current (Ipk): 75kA
Short Circuit Current Rating (SCCR): 100kA
Max Working Voltage, IEC (Ui): 1000; 1500
Max Working Voltage, UL (Vin): 1000
Number of Stud Connections: 4
Stud Connection Conductor Width: (2) 20 – 40 mm; (1) 50 – 80 mm
Stud Connection Compact Stranded Wire Size: (2) 25 – 300 mm²
Stud Connection Wire Size: (2) #4 - 500 kcmil
Dybde (D): 75mm
Height (H): 205.7mm
Width (W): 115mm
A: 108mm
Unit Weight: 0.7kg
Certification Details: UL® 1059
Flammability Rating: UL® 94V-1
Complies With: IEC® 60947-7-1

YDERLIGERE PRODUKTOPLYSNINGER

Power terminal connections are interchangeable and can be used as line side or load side connections.

Design Guideline for Distribution Blocks, Power Blocks and Power Terminals										
Derating according to Ambient* Temperature (°C) to maintain working temperature of 85°C										
Ambient Temperature (°C)	30°	35°	40°	45°	50°	55°	60°	65°	70°	75°
Derating Coefficient (d)	1	1	1	0.94	0.88	0.82	0.75	0.67	0.58	0.47
*environment around the terminal blocks inside the enclosure										

DIAGRAMS

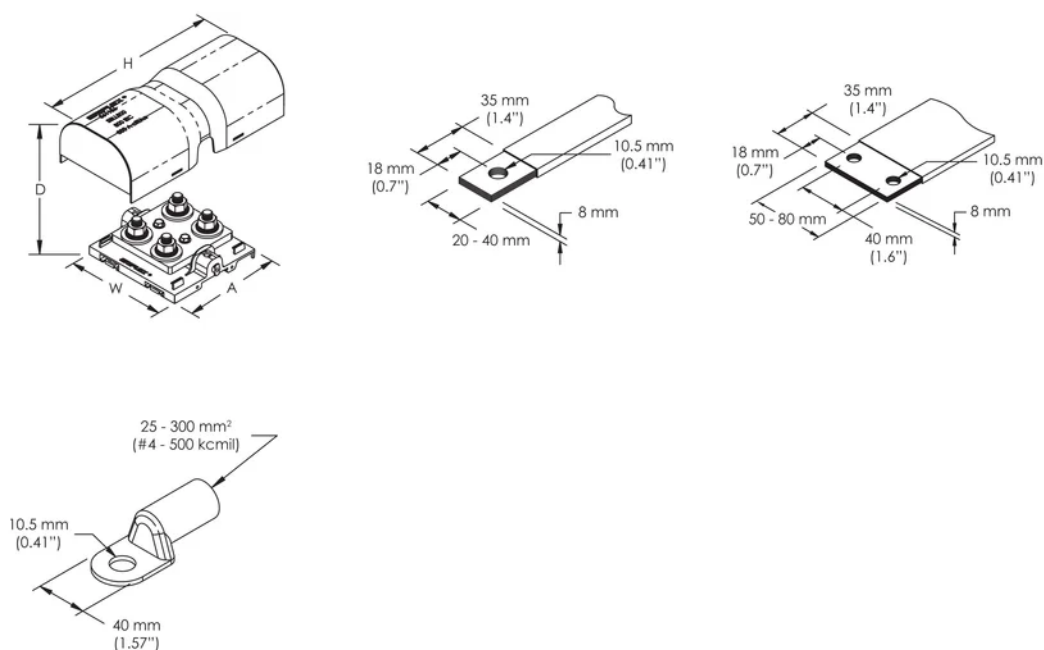

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE