


# Four Pole Distrib. Block, 160 A, 1 Line Side & 11 Load Side Connections, 50mm Dp

## Data Solutions

### KATALOGNUMMER

---

**TD-160A**

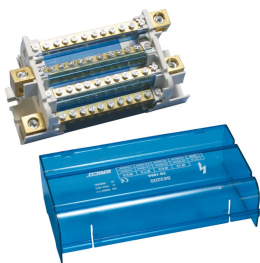

### CERTIFICERINGER

---



### FUNKTIONER

---

Minimum space for maximum power

Protection cover and insulating screens are transparent

Insulating screen between each row

Easy and safe connections

Easily clips onto DIN rail or mounts to panel with screws

Solid bars provide reliability

Input separated from outputs

Neutral bar available

Wiring with or without terminal

RoHS compliant

Conforms to EN 45545 obtaining an HL3 classification for chapter R23 and HL2 classification for chapter R22

Halogen free

## PRODUKTEGENSKABER

Artikelnummer: 563200

Materiale: Thermoplastic; Brass

Max Current Rating, IEC: 160A

Short Term Withstand Current (Icw) 1s: 8.2kA

Peak Short Circuit Current (Ipk): 35kA

Max Working Voltage, IEC (Ui): 690V

Line Side Number of Connections: 1

Line Side Compact Stranded Wire Size: 10 - 50 mm<sup>2</sup>

Line Side Stranded Wire Size - Ferrule: 10 – 50mm<sup>2</sup>

Load Side Number of Connections: 11

Load Side Compact Stranded Wire Size: (1) 2,5 - 6 mm<sup>2</sup>; (7) 2,5 - 16 mm<sup>2</sup>; (3) 10 - 35 mm<sup>2</sup>

Load Side Stranded Wire Size - Ferrule: (1) 1,5 – 6 mm<sup>2</sup>; (7) 1,5 – 16 mm<sup>2</sup>; (3) 10 – 25 mm<sup>2</sup>

Dybde (D): 50mm

Height (H): 90mm

Width (W): 175mm

Unit Weight: 0.61kg

Flammability Rating: UL® 94V-0

Complies With: IEC® 60947-7-1

## YDERLIGERE PRODUKTOPLYSNINGER

Line side and load side number of connections are per pole.

### Design Guideline for Distribution Blocks, Power Blocks and Power Terminals


Derating according to Ambient\* Temperature (°C) to maintain working temperature of 85°C

| Ambient Temperature (°C) | 30° | 35° | 40° | 45°  | 50°  | 55°  | 60°  | 65°  | 70°  | 75°  |
|--------------------------|-----|-----|-----|------|------|------|------|------|------|------|
| Derating Coefficient (d) | 1   | 1   | 1   | 0.94 | 0.88 | 0.82 | 0.75 | 0.67 | 0.58 | 0.47 |

\*environment around the terminal blocks inside the enclosure

## DIAGRAMS

---

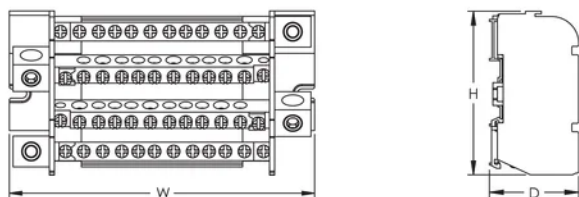

## ADVARSEL

---

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**