

Four Pole Distrib. Block with Threaded Bars, Flat, 400 A

Data Solutions

KATALOGNUMMER

TRC-400A



CERTIFICERINGER



FUNKTIONER

Transparent protection cover

Bolts included for output connections

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

PRODUKTEGENSKABER

Artikelnummer: 563180

Materiale: Copper; Glass Fibre Reinforced Polyamide; Plexiglass

Max Working Voltage, IEC (Ui): 1000

Peak Short Circuit Current (I_{pk}): 118kA

Short Term Withstand Current (I_{cw}) 1s: 28kA

Line Side Number of Connections: 1

Load Side Number of Connections: 10

Thread Size 1 (TS1): M6

Thread Size 2 (TS2): M10

Dybde (D): 50mm

Height (H): 338 – 390mm

Width (W): 260mm

A: 290mm

Unit Weight: 2.65kg

Flammability Rating: UL® 94V-0


Complies With: IEC® 60439.1; IEC® 61439.1; IEC® 60695-2-11 (Glow Wire Test 960 °C)

YDERLIGERE PRODUKTOPLYSNINGER

Thread Size 2 represents input plug.

Line side and load side number of connections are per pole.

DIAGRAMS

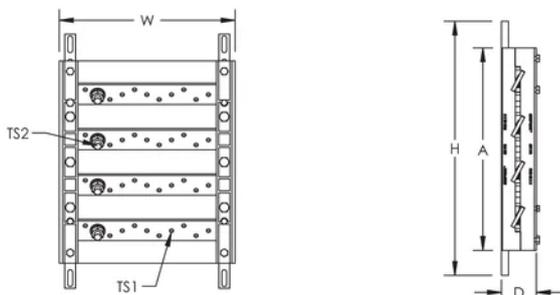

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE