

# Four Pole Distrib. Block with Threaded Bars, Flat, 630 A

## Data Solutions

### KATALOGNUMMER

---

**TRC-630A**



### CERTIFICERINGER

---



### FUNKTIONER

---

Transparent protection cover

Bolts included for output connections

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

### PRODUKTEGENSKABER

---

Artikelnummer: 563190

Materiale: Copper; Glass Fibre Reinforced Polyamide; Plexiglass

Max Working Voltage, IEC (Ui): 1000

Peak Short Circuit Current (I<sub>pk</sub>): 84kA

Short Term Withstand Current (I<sub>cw</sub>) 1s: 52kA

Line Side Number of Connections: 1

Load Side Number of Connections: 8

Hole Size (HS): 10mm

Thread Size (TS): M8

Dybde (D): 60mm

Height (H): 338 – 390mm

Width (W): 340mm

A: 290mm

Unit Weight: 4.8kg

Flammability Rating: UL® 94V-0

Complies With: IEC® 60439.1; IEC® 61439.1; IEC® 60695-2-11 (Glow Wire Test 960 °C)


## YDERLIGERE PRODUKTOPLYSNINGER

---

Line side and load side number of connections are per pole.

## DIAGRAMS

---

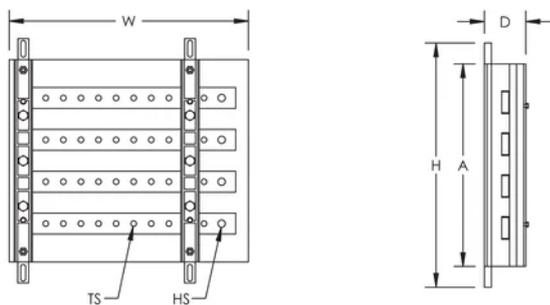

## ADVARSEL

---

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**