

Four Pole Distrib. Block with Threaded Bars, 160 A

Data Solutions

KATALOGNUMMER

TRS-160A



CERTIFICERINGER



FUNKTIONER

- Easily fixes onto asymmetric DIN rail or mounts with screws
- Bolts included for output connections
- Transparent protection cover
- Easy accessibility for wiring
- Ready to use out of the box, saving installation time and labor
- RoHS compliant

PRODUKTEGENSKABER

- Artikelnummer: 563160
- Materiale: Copper; Glass Fibre Reinforced Polyamide; Plexiglass

Max Working Voltage, IEC (Ui): 630

Peak Short Circuit Current (Ipk): 34kA

Short Term Withstand Current (Icw) 1s: 13.2kA

Line Side Number of Connections: 2

Load Side Number of Connections: 4

Hole Size (HS): 8mm

Thread Size (TS): M6

Dybde (D): 68mm

Height (H): 150mm

Width (W): 230mm

Unit Weight: 1.15kg


Flammability Rating: UL® 94V-0

Complies With: IEC® 60439.1; IEC® 61439.1; IEC® 60695-2-11 (Glow Wire Test 960 °C)

YDERLIGERE PRODUKTOPLYSNINGER

Line side and load side number of connections are per pole.

DIAGRAMS

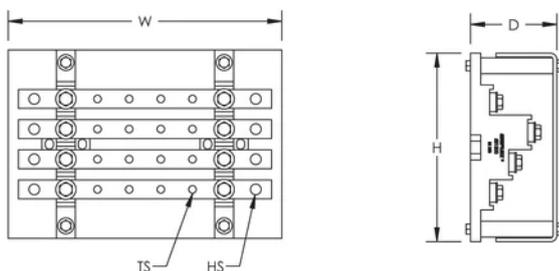

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE