


# Door Contact Switch Without Cable

## Data Solutions

### KATALOGNUMMER

**20118-810**

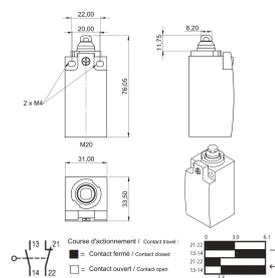

Door contact switch with magnetic contact, allows operational efficiency. This product is easy handlable by plug and play.

### CERTIFICERINGER



### FUNKTIONER

Door contact switch (without connection cable)

### PRODUKTEGENSKABER

Product Type: Switch

Dybde: 33.5mm

Højde: 76.5mm

Driftstemperatur: -25 to 75°C

Beskyttelsesgrad: IP66

Bredde: 31mm

Complies With: UL® 508; EN 50047 form B

Current Rating: 3 – 6A

Gross Weight: 0.1kg

Pakke mængde: 1

Voltage: 24 – 230V

Trådstørrelse: 0.5 – 2.5mm<sup>2</sup>

## YDERLIGERE PRODUKTOPLYSNINGER

---

Please order bracket for installation of door switch (Varistar, Novastar, Eurorack) separately.

## ADVARSEL

---

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unkladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**