


# Varistar CP Double Steel Door, Perforated, 3-Point Locking, RAL 7021, 52 U, 2450H, 600W

## Data Solutions

### KATALOGNUMMER

---

**21630-022**

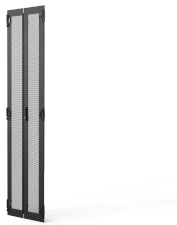

Perforated Varistar CP steel double door with 3-point locking for applications with IP 20 protection

### FUNKTIONER

---

Double perforated steel door with 3 point locking for IP 20 protection class

Lever handle with key insert (2 keys)

Opening angle 180°

Standard fitting, lock on right-hand door

Can be retrofitted with lever handle 24630003 and DIN profile half cylinder with keys or push button

### PRODUKTEGENSKABER

---

Rack Height: 52U

Højde: 2450mm

Bredde: 600mm

Pakke mængde: 1

Farve: Black Grey

Farvekode: RAL 7021

Complies With: IEC 61587-1; IEC 61587-3

Finish: Struktur Pulvermaling

Locking Type: 3-Point Locking

Materiale: Stål

Produktfamilie: Varistar CP

Product Type: Cabinet Door

Beskyttelsesgrad: IP20

Type: Steel Double Door, Perforated

Works With: Varistar CP

Net Weight: 20.058kg

## YDERLIGERE PRODUKTOPLYSNINGER

---

24U - 33U IP20 doors have 2 hinges, 38U - 52U IP20 doors have 3 hinges to ensure robust IP20 closing structures for taller cabinets

Please order lever handle 24630003 and the DIN lock separately if you want to replace the 1333 DIN lock lever handle

Please purchase the grounding kit separately.

## ADVARSEL

---

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer.

Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unkladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**