


# 19" Front Panel With Holes for Handles, 2 U, 3 mm, Al, Anodized, Untreated Edges

## Data Solutions

### KATALOGNUMMER

**30219-162**

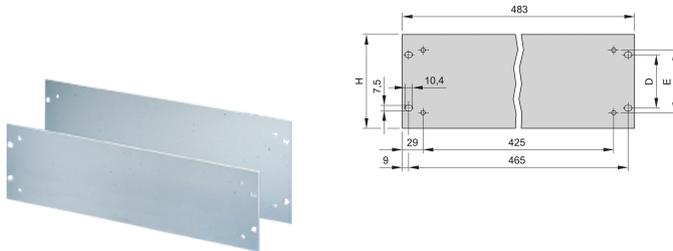

Define the device fronts and side inss with Schroff 19" front panels. Schroff 19" front panels have additional holes for mounting of handles and are available in 1 U to 6 U demensions.

### CERTIFICERINGER



### FUNKTIONER

19" front panels have additional holes for mounting of handles

### PRODUKTEGENSKABER

Rack Height: 2U

Dybde (D): 3mm

Accessory Type: Front panel

Håndtagstype: Front Handle

Finish: Anodized

Mounting: Screw-on Front

Pakke mængde: 1

Front Finish: Anodized

Rear Finish: Anodized

Treated Edges: No

EMC Shielding: No

Højde (H): 88.1mm

Materiale: Aluminium

Product Type: Front Panel

Rack Width: 95HP

Type: 19" Front Panel

Bredde (W): 483mm

Net Weight: 0.335kg

## DIAGRAMS



## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**