


19" Front Panel With Holes for Handles, 3 U, 4 mm, Al, Anodized

Data Solutions

KATALOGNUMMER

40304-052

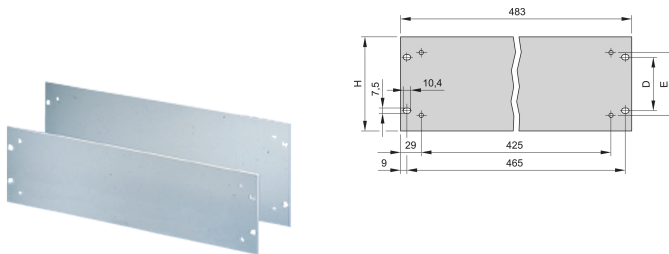

Define the device fronts and side inss with Schroff 19" front panels. Schroff 19" front panels have additional holes for mounting of handles and are available in 1 U to 6 U demensions.

CERTIFICERINGER



FUNKTIONER

19" front panels have additional holes for mounting of handles

PRODUKTEGENSKABER

Rack Height: 3U

Dybde (D): 3mm

Accessory Type: Front panel

Håndtagstype: Front Handle

Finish: Anodized

Mounting: Screw-on Front

Pakke mængde: 1

Front Finish: Anodized

Rear Finish: Anodized

Treated Edges: Yes

EMC Shielding: No

Højde (H): 132.5mm

Materiale: Aluminium

Product Type: Front Panel


Rack Width: 95HP

Type: 19" Front Panel

Bredde (W): 483mm

Gross Weight: 0.664kg

DIAGRAMS

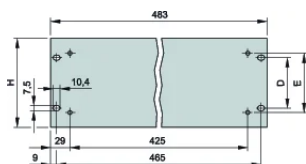

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE