

PEMSA Wire Basket Tray

Data Solutions



The PEMS A Wire Basket Tray is the backbone of PEMS A Wire Basket Tray System. Highly engineered features help ensure a secure installation that complies with industry codes and standards for high-performance cables. Clever design allows the installer to maximize field efficiency with the Rejiband Rapide Integrated Splice.

CERTIFICERINGER



FUNKTIONER

Provides optimal support for high-performance low voltage and data cables

Innovative Rejiband Rapide installation system

IEC 61537 load rating and earthing compliant

Responsive design and layout services, including seismic

SPECIFIKATIONER

Table 1/6

| Katalognummer | Artikelnummer | Farve | Materiale | Finish | Length (L) | Height (H) |
|---------------|---------------|-------|---------------------------------|-------------------|------------|------------|
| WBT35X60S4 | 821003 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 35mm |
| WBT35X60EG | 821000 | | Carbon Steel | Electrogalvanized | 3000mm | 35mm |

| Katalognummer | Artikelnummer | Farve | Materiale | Finish | Length (L) | Height (H) |
|---------------|---------------|-------|---------------------------------|-----------------------|------------|------------|
| WBT35X60BA | 821001 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 35mm |
| WBT35X400BA | 821051 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 35mm |
| WBT35X100EG | 821010 | | Carbon Steel | Electrogalvanized | 3000mm | 35mm |
| WBT35X400S4 | 821053 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 35mm |
| WBT35X400EG | 821050 | | Carbon Steel | Electrogalvanized | 3000mm | 35mm |
| WBT35X150BA | 821021 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 35mm |
| WBT35X300S4 | 821043 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 35mm |
| WBT35X300EG | 821040 | | Carbon Steel | Electrogalvanized | 3000mm | 35mm |
| WBT35X300BA | 821041 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 35mm |
| WBT35X200S4 | 821033 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 35mm |
| WBT35X200EG | 821030 | | Carbon Steel | Electrogalvanized | 3000mm | 35mm |
| WBT35X100S4 | 821013 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 35mm |
| WBT35X200BA | 821031 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 35mm |
| WBT35X100BA | 821011 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 35mm |
| WBT35X150EG | 821020 | | Carbon Steel | Electrogalvanized | 3000mm | 35mm |
| WBT35X150S4 | 821023 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 35mm |
| WBT60X60S4 | 820003 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 60mm |

| Katalognummer | Artikelnummer | Farve | Materiale | Finish | Length (L) | Height (H) |
|---------------|---------------|-------|--------------|-------------------|------------|------------|
| WBT60X60EG | 820000 | | Carbon Steel | Electrogalvanized | 3000mm | 60mm |

Table 2/6

| Katalognummer | Artikelnummer | Farve | Materiale | Finish | Length (L) | Height (H) |
|---------------|---------------|-------|---------------------------------|-----------------------|------------|------------|
| WBT60X60BG | 820002 | Black | Carbon Steel | Electrogalvanized | 3000mm | 60mm |
| WBT60X60BA | 820001 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 60mm |
| WBT60X600EG | 820074 | | Carbon Steel | Electrogalvanized | 3000mm | 60mm |
| WBT60X200BA | 820031 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 60mm |
| WBT60X400BA | 820051 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 60mm |
| WBT60X600BA | 820075 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 60mm |
| WBT60X200BG | 820032 | Black | Carbon Steel | Electrogalvanized | 3000mm | 60mm |
| WBT60X600BG | 820076 | Black | Carbon Steel | Electrogalvanized | 3000mm | 60mm |
| WBT60X300S4 | 820043 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 60mm |
| WBT60X200EG | 820030 | | Carbon Steel | Electrogalvanized | 3000mm | 60mm |
| WBT60X150S4 | 820023 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 60mm |
| WBT60X200S4 | 820033 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 60mm |
| WBT60X300EG | 820040 | | Carbon Steel | Electrogalvanized | 3000mm | 60mm |
| WBT60X300BA | 820041 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 60mm |
| WBT60X600S4 | 820077 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 60mm |

| Katalognummer | Artikelnummer | Farve | Materiale | Finish | Length (L) | Height (H) |
|---------------|---------------|-------|--------------|-----------------------|------------|------------|
| WBT60X300BG | 820042 | Black | Carbon Steel | Electrogalvanized | 3000mm | 60mm |
| WBT60X150BA | 820021 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 60mm |
| WBT60X450EG | 820080 | | Carbon Steel | Electrogalvanized | 3000mm | 60mm |
| WBT60X500BA | 820061 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 60mm |
| WBT60X100EG | 820010 | | Carbon Steel | Electrogalvanized | 3000mm | 60mm |

Table 3/6

| Katalognummer | Artikelnummer | Farve | Materiale | Finish | Length (L) | Height (H) |
|---------------|---------------|-------|---------------------------------|-----------------------|------------|------------|
| WBT60X100BA | 820011 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 60mm |
| WBT60X450BG | 820082 | Black | Carbon Steel | Electrogalvanized | 3000mm | 60mm |
| WBT60X100S4 | 820013 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 60mm |
| WBT60X450BA | 820081 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 60mm |
| WBT60X500BG | 820062 | Black | Carbon Steel | Electrogalvanized | 3000mm | 60mm |
| WBT60X500S4 | 820063 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 60mm |
| WBT60X400S4 | 820053 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 60mm |
| WBT60X150BG | 820022 | Black | Carbon Steel | Electrogalvanized | 3000mm | 60mm |
| WBT60X500EG | 820060 | | Carbon Steel | Electrogalvanized | 3000mm | 60mm |
| WBT60X400EG | 820050 | | Carbon Steel | Electrogalvanized | 3000mm | 60mm |
| WBT60X150EG | 820020 | | Carbon Steel | Electrogalvanized | 3000mm | 60mm |
| WBT60X400BG | 820052 | Black | Carbon Steel | Electrogalvanized | 3000mm | 60mm |

| Katalognummer | Artikelnummer | Farve | Materiale | Finish | Length (L) | Height (H) |
|---------------|---------------|-------|---------------------------------|-----------------------|------------|------------|
| WBT60X100BG | 820012 | Black | Carbon Steel | Electrogalvanized | 3000mm | 60mm |
| WBT100X100EG | 823010 | | Carbon Steel | Electrogalvanized | 3000mm | 100mm |
| WBT100X100S4 | 823013 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 100mm |
| WBT100X100BA | 823011 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 100mm |
| WBT100X100BG | 823012 | Black | Carbon Steel | Electrogalvanized | 3000mm | 100mm |
| WBT100X150BG | 823022 | Black | Carbon Steel | Electrogalvanized | 3000mm | 100mm |
| WBT100X150BA | 823021 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 100mm |
| WBT100X150EG | 823020 | | Carbon Steel | Electrogalvanized | 3000mm | 100mm |

Table 4/6

| Katalognummer | Artikelnummer | Farve | Materiale | Finish | Length (L) | Height (H) |
|---------------|---------------|-------|---------------------------------|-----------------------|------------|------------|
| WBT100X150S4 | 823023 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 100mm |
| WBT100X300BA | 823041 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 100mm |
| WBT100X450BG | 823082 | Black | Carbon Steel | Electrogalvanized | 3000mm | 100mm |
| WBT100X400BG | 823052 | Black | Carbon Steel | Electrogalvanized | 3000mm | 100mm |
| WBT100X400EG | 823050 | | Carbon Steel | Electrogalvanized | 3000mm | 100mm |
| WBT100X300S4 | 823043 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 100mm |
| WBT100X400BA | 823051 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 100mm |
| WBT100X300EG | 823040 | | Carbon Steel | Electrogalvanized | 3000mm | 100mm |
| WBT100X300BG | 823042 | Black | Carbon Steel | Electrogalvanized | 3000mm | 100mm |

| Katalognummer | Artikelnummer | Farve | Materiale | Finish | Length (L) | Height (H) |
|---------------|---------------|-------|---------------------------------|-----------------------|------------|------------|
| WBT100X450BA | 823081 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 100mm |
| WBT100X400S4 | 823053 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 100mm |
| WBT100X600S4 | 823073 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 100mm |
| WBT100X500S4 | 823063 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 100mm |
| WBT100X200BA | 823031 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 100mm |
| WBT100X500BA | 823061 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 100mm |
| WBT100X200EG | 823030 | | Carbon Steel | Electrogalvanized | 3000mm | 100mm |
| WBT100X500EG | 823060 | | Carbon Steel | Electrogalvanized | 3000mm | 100mm |
| WBT100X500BG | 823062 | Black | Carbon Steel | Electrogalvanized | 3000mm | 100mm |
| WBT100X200BG | 823032 | Black | Carbon Steel | Electrogalvanized | 3000mm | 100mm |
| WBT100X450EG | 823080 | | Carbon Steel | Electrogalvanized | 3000mm | 100mm |

Table 5/6

| Katalognummer | Artikelnummer | Farve | Materiale | Finish | Length (L) | Height (H) |
|---------------|---------------|-------|---------------------------------|-----------------------|------------|------------|
| WBT100X200S4 | 823033 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 100mm |
| WBT100X600EG | 823070 | | Carbon Steel | Electrogalvanized | 3000mm | 100mm |
| WBT100X600BG | 823072 | Black | Carbon Steel | Electrogalvanized | 3000mm | 100mm |
| WBT100X600BA | 823071 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 100mm |
| WBT150X300BA | 825041 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 150mm |

| Katalognummer | Artikelnummer | Farve | Materiale | Finish | Length (L) | Height (H) |
|---------------|---------------|-------|---------------------------------|-----------------------|------------|------------|
| WBT150X200S4 | 825033 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 150mm |
| WBT150X900EG | 825090 | | Carbon Steel | Electrogalvanized | 3000mm | 150mm |
| WBT150X200EG | 825030 | | Carbon Steel | Electrogalvanized | 3000mm | 150mm |
| WBT150X200BA | 825031 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 150mm |
| WBT150X200BG | 825032 | Black | Carbon Steel | Electrogalvanized | 3000mm | 150mm |
| WBT150X450EG | 825080 | | Carbon Steel | Electrogalvanized | 3000mm | 150mm |
| WBT150X600BG | 825072 | Black | Carbon Steel | Electrogalvanized | 3000mm | 150mm |
| WBT150X400BG | 825052 | Black | Carbon Steel | Electrogalvanized | 3000mm | 150mm |
| WBT150X400EG | 825050 | | Carbon Steel | Electrogalvanized | 3000mm | 150mm |
| WBT150X400S4 | 825053 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 150mm |
| WBT150X450BA | 825081 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 150mm |
| WBT150X450BG | 825082 | Black | Carbon Steel | Electrogalvanized | 3000mm | 150mm |
| WBT150X900BG | 825092 | Black | Carbon Steel | Electrogalvanized | 3000mm | 150mm |
| WBT150X900BA | 825091 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 150mm |
| WBT150X600BA | 825071 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 150mm |

Table 6/6

| Katalognummer | Artikelnummer | Farve | Materiale | Finish | Length (L) | Height (H) |
|---------------|---------------|-------|---------------------------------|-----------------------|------------|------------|
| WBT150X450S4 | 825083 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 150mm |
| WBT150X500BA | 825061 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 150mm |

| Katalognummer | Artikelnummer | Farve | Materiale | Finish | Length (L) | Height (H) |
|---------------|---------------|-------|---------------------------------|-----------------------|------------|------------|
| WBT150X500S4 | 825063 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 150mm |
| WBT150X500EG | 825060 | | Carbon Steel | Electrogalvanized | 3000mm | 150mm |
| WBT150X600S4 | 825073 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 150mm |
| WBT150X500BG | 825062 | Black | Carbon Steel | Electrogalvanized | 3000mm | 150mm |
| WBT150X300EG | 825040 | | Carbon Steel | Electrogalvanized | 3000mm | 150mm |
| WBT150X400BA | 825051 | Black | Carbon Steel | Struktur Pulvermaling | 3000mm | 150mm |
| WBT150X600EG | 825070 | | Carbon Steel | Electrogalvanized | 3000mm | 150mm |
| WBT150X300BG | 825042 | Black | Carbon Steel | Electrogalvanized | 3000mm | 150mm |
| WBT150X300S4 | 825043 | | Stainless Steel 304 (EN 1.4301) | | 3000mm | 150mm |

Table 1/6

| Katalognummer | Artikelnummer | Width (W) | Unit Weight | Certificeringer |
|---------------|---------------|-----------|-------------|--|
| WBT35X60S4 | 821003 | 60mm | 1.19kg | CE, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT35X60EG | 821000 | 60mm | 1.2kg | CE, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT35X60BA | 821001 | 60mm | 1.2kg | |
| WBT35X400BA | 821051 | 400mm | 4.29kg | |
| WBT35X100EG | 821010 | 100mm | 1.62kg | ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, CE, CADDY EU WBT |
| WBT35X400S4 | 821053 | 400mm | 5.22kg | ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT |

| Katalognummer | Artikelnummer | Width (W) | Unit Weight | Certificeringer |
|---------------|---------------|-----------|-------------|--|
| WBT35X400EG | 821050 | 400mm | 4.29kg | CE, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT35X150BA | 821021 | 150mm | 1.76kg | |
| WBT35X300S4 | 821043 | 300mm | 4.13kg | ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT35X300EG | 821040 | 300mm | 3.42kg | CE, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT35X300BA | 821041 | 300mm | 3.42kg | |
| WBT35X200S4 | 821033 | 200mm | 3.04kg | ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT35X200EG | 821030 | 200mm | 2.5kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT35X100S4 | 821013 | 100mm | 1.61kg | CE, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT35X200BA | 821031 | 200mm | 2.5kg | |
| WBT35X100BA | 821011 | 100mm | 1.62kg | |
| WBT35X150EG | 821020 | 150mm | 1.76kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT35X150S4 | 821023 | 150mm | 2.12kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT |
| WBT60X60S4 | 820003 | 60mm | 2.32kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT |
| WBT60X60EG | 820000 | 60mm | 2.32kg | CE, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG |

Table 2/6

| Katalognummer | Artikelnummer | Width (W) | Unit Weight | Certificeringer |
|---------------|---------------|-----------|-------------|-----------------|
|---------------|---------------|-----------|-------------|-----------------|

| | | | | |
|-------------|--------|-------|--------|---|
| WBT60X60BG | 820002 | 60mm | 2.32kg | ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT60X60BA | 820001 | 60mm | 2.32kg | |
| WBT60X600EG | 820074 | 600mm | 8.43kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT60X200BA | 820031 | 200mm | 3.33kg | |
| WBT60X400BA | 820051 | 400mm | 6.21kg | |
| WBT60X600BA | 820075 | 600mm | 8.43kg | |
| WBT60X200BG | 820032 | 200mm | 3.33kg | CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT60X600BG | 820076 | 600mm | 8.43kg | ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT60X300S4 | 820043 | 300mm | 5.13kg | DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT60X200EG | 820030 | 200mm | 3.33kg | DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT60X150S4 | 820023 | 150mm | 2.6kg | DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT60X200S4 | 820033 | 200mm | 3.33kg | ANOR EU WTB EG S4 BG, DoP, CADDY EU WBT, UKCA, CADDY EU WBT, CE, CADDY EU WBT |
| WBT60X300EG | 820040 | 300mm | 5.13kg | DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, CE, CADDY EU WBT |

| | | | | |
|-------------|--------|-------|--------|---|
| WBT60X300BA | 820041 | 300mm | 5.13kg | |
| WBT60X600S4 | 820077 | 600mm | 8.43kg | CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT60X300BG | 820042 | 300mm | 5.13kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT60X150BA | 820021 | 150mm | 2.6kg | |
| WBT60X450EG | 820080 | 450mm | 6.39kg | ANOR EU WTB EG S4 BG, DoP, CADDY EU WBT, UKCA, CADDY EU WBT, CE, CADDY EU WBT |
| WBT60X500BA | 820061 | 500mm | 7.35kg | |
| WBT60X100EG | 820010 | 100mm | 2.43kg | DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT |

Table 3/6

| Katalognummer | Artikelnummer | Width (W) | Unit Weight | Certificeringer |
|---------------|---------------|-----------|-------------|---|
| WBT60X100BA | 820011 | 100mm | 2.43kg | |
| WBT60X450BG | 820082 | 450mm | 6.39kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT60X100S4 | 820013 | 100mm | 2.43kg | ANOR EU WTB EG S4 BG, DoP, CADDY EU WBT, CE, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT60X450BA | 820081 | 450mm | 6.39kg | |
| WBT60X500BG | 820062 | 500mm | 7.35kg | ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT60X500S4 | 820063 | 500mm | 7.35kg | CE, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG |

| Katalognummer | Artikelnummer | Width (W) | Unit Weight | Certificeringer |
|---------------|---------------|-----------|-------------|---|
| WBT60X400S4 | 820053 | 400mm | 6.21kg | ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, CE, CADDY EU WBT |
| WBT60X150BG | 820022 | 150mm | 2.6kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG, DoP, CADDY EU WBT |
| WBT60X500EG | 820060 | 500mm | 7.35kg | CE, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT60X400EG | 820050 | 400mm | 6.21kg | DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, CE, CADDY EU WBT |
| WBT60X150EG | 820020 | 150mm | 2.6kg | DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT60X400BG | 820052 | 400mm | 6.21kg | CE, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG, DoP, CADDY EU WBT |
| WBT60X100BG | 820012 | 100mm | 2.43kg | CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT100X100EG | 823010 | 100mm | 3.27kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG, DoP, CADDY EU WBT |
| WBT100X100S4 | 823013 | 100mm | 3.27kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG, DoP, CADDY EU WBT |
| WBT100X100BA | 823011 | 100mm | 3.27kg | |

| Katalognummer | Artikelnummer | Width (W) | Unit Weight | Certificeringer |
|---------------|---------------|-----------|-------------|---|
| WBT100X100BG | 823012 | 100mm | 3.27kg | DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT100X150BG | 823022 | 150mm | 3.45kg | DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, CE, CADDY EU WBT |
| WBT100X150BA | 823021 | 150mm | 3.45kg | |
| WBT100X150EG | 823020 | 150mm | 3.45kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG, DoP, CADDY EU WBT |

Table 4/6

| Katalognummer | Artikelnummer | Width (W) | Unit Weight | Certificeringer |
|---------------|---------------|-----------|-------------|---|
| WBT100X150S4 | 823023 | 150mm | 3.45kg | CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT100X300BA | 823041 | 300mm | 6.15kg | |
| WBT100X450BG | 823082 | 450mm | 7.44kg | ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, CE, CADDY EU WBT |
| WBT100X400BG | 823052 | 400mm | 7.23kg | ANOR EU WTB EG S4 BG, DoP, CADDY EU WBT, CE, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT100X400EG | 823050 | 400mm | 7.23kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT100X300S4 | 823043 | 300mm | 6.15kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG, DoP, CADDY EU WBT |
| WBT100X400BA | 823051 | 400mm | 7.23kg | |

| Katalognummer | Artikelnummer | Width (W) | Unit Weight | Certificeringer |
|---------------|---------------|-----------|-------------|---|
| WBT100X300EG | 823040 | 300mm | 6.15kg | CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT100X300BG | 823042 | 300mm | 6.15kg | DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT100X450BA | 823081 | 450mm | 7.44kg | |
| WBT100X400S4 | 823053 | 400mm | 7.23kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT100X600S4 | 823073 | 600mm | 9.42kg | ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT100X500S4 | 823063 | 500mm | 8.34kg | ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT100X200BA | 823031 | 200mm | 4.14kg | |
| WBT100X500BA | 823061 | 500mm | 8.34kg | |
| WBT100X200EG | 823030 | 200mm | 4.14kg | CE, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG, DoP, CADDY EU WBT |
| WBT100X500EG | 823060 | 500mm | 8.34kg | ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, CE, CADDY EU WBT |
| WBT100X500BG | 823062 | 500mm | 8.34kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT100X200BG | 823032 | 200mm | 4.14kg | ANOR EU WTB EG S4 BG, DoP, CADDY EU WBT, CE, CADDY EU WBT, UKCA, CADDY EU WBT |

| Katalognummer | Artikelnummer | Width (W) | Unit Weight | Certificeringer |
|---------------|---------------|-----------|-------------|---|
| WBT100X450EG | 823080 | 450mm | 7.44kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG |

Table 5/6


| Katalognummer | Artikelnummer | Width (W) | Unit Weight | Certificeringer |
|---------------|---------------|-----------|-------------|---|
| WBT100X200S4 | 823033 | 200mm | 4.14kg | CE, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG, DoP, CADDY EU WBT |
| WBT100X600EG | 823070 | 600mm | 9.42kg | ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, CE, CADDY EU WBT |
| WBT100X600BG | 823072 | 600mm | 9.42kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT100X600BA | 823071 | 600mm | 9.42kg | |
| WBT150X300BA | 825041 | 300mm | 7.29kg | |
| WBT150X200S4 | 825033 | 200mm | 6.01kg | CE, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT150X900EG | 825090 | 900mm | 15.98kg | |
| WBT150X200EG | 825030 | 200mm | 6.01kg | CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT |
| WBT150X200BA | 825031 | 200mm | 6.01kg | |
| WBT150X200BG | 825032 | 200mm | 6.01kg | CE, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT150X450EG | 825080 | 450mm | 8.68kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT |
| WBT150X600BG | 825072 | 600mm | 10.65kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT |
| WBT150X400BG | 825052 | 400mm | 8.47kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT |
| WBT150X400EG | 825050 | 400mm | 8.47kg | CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT |

| Katalognummer | Artikelnummer | Width (W) | Unit Weight | Certificeringer |
|---------------|---------------|-----------|-------------|--------------------------------------|
| WBT150X400S4 | 825053 | 400mm | 8.47kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT |
| WBT150X450BA | 825081 | 450mm | 8.68kg | |
| WBT150X450BG | 825082 | 450mm | 8.68kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT |
| WBT150X900BG | 825092 | 900mm | 15.98kg | |
| WBT150X900BA | 825091 | 900mm | 15.98kg | |
| WBT150X600BA | 825071 | 600mm | 10.65kg | |

Table 6/6

| Katalognummer | Artikelnummer | Width (W) | Unit Weight | Certificeringer |
|---------------|---------------|-----------|-------------|---|
| WBT150X450S4 | 825083 | 450mm | 8.68kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT |
| WBT150X500BA | 825061 | 500mm | 9.7kg | |
| WBT150X500S4 | 825063 | 500mm | 9.7kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT |
| WBT150X500EG | 825060 | 500mm | 9.7kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT |
| WBT150X600S4 | 825073 | 600mm | 10.65kg | CE, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT150X500BG | 825062 | 500mm | 9.7kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT |
| WBT150X300EG | 825040 | 300mm | 7.29kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT, DoP, CADDY EU WBT |
| WBT150X400BA | 825051 | 400mm | 8.47kg | |
| WBT150X600EG | 825070 | 600mm | 10.65kg | CE, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT150X300BG | 825042 | 300mm | 7.29kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT |
| WBT150X300S4 | 825043 | 300mm | 7.29kg | UKCA, CADDY EU WBT, CE, CADDY EU WBT |

DIAGRAMS

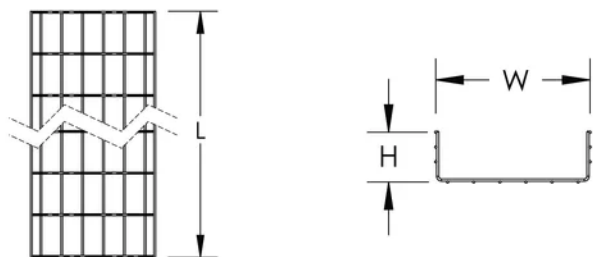

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE