


# TR Four Pole Distribution Block, 125 A

## Data Solutions

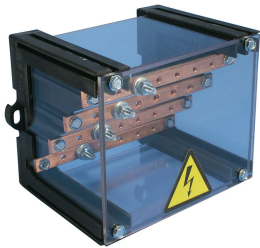

### CERTIFICERINGER



### FUNKTIONER

Easily clips onto DIN rail or mounts to panel with screws

Equipped with a current input plug

Bolts included for output connections

Transparent protection cover

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

### SPECIFIKATIONER

<b>Katalognummer</b>	<b>TR-125A</b>
Artikelnummer	563150
Materiale	Copper Glass Fibre Reinforced Polyamide Plexiglass


<b>Katalognummer</b>	<b>TR-125A</b>
Max Working Voltage, IEC (Ui)	1000
Peak Short Circuit Current (Ipk)	40kA
Short Term Withstand Current (Icw) 1s	8.4kA
Line Side Number of Connections	1
Load Side Number of Connections	5
Thread Size 1 (TS1)	M5
Thread Size 2 (TS2)	M6
Dybde (D)	117mm
Height (H)	126mm
Width (W)	150mm
Unit Weight	0.68kg
Flammability Rating	UL® 94V-0
Complies With	IEC® 60439.1 IEC® 61439.1 IEC® 60695-2-11 (Glow Wire Test 960 °C)

## YDERLIGERE PRODUKTOPLYSNINGER

Thread Size 2 represents input plug.

Line side and load side number of connections are per pole.

## DIAGRAMS

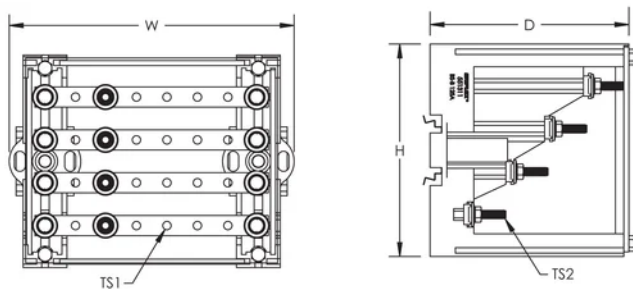

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**