

TRC Four Pole Distribution Block, 400 A

Data Solutions



CERTIFICERINGER



FUNKTIONER

Transparent protection cover

Bolts included for output connections

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

SPECIFIKATIONER

Table 1/2

Katalognummer	TRC-400A
Artikelnummer	563180
Materiale	Copper Glass Fibre Reinforced Polyamide Plexiglass

Katalognummer	TRC-400A
Max Working Voltage, IEC (Ui)	1000
Peak Short Circuit Current (Ipk)	118kA
Short Term Withstand Current (Icw) 1s	28kA
Line Side Number of Connections	1
Load Side Number of Connections	10
Thread Size 1 (TS1)	M6
Thread Size 2 (TS2)	M10
Dybde (D)	50mm
Height (H)	338 – 390mm
Width (W)	260mm
A	290mm
Unit Weight	2.65kg
Flammability Rating	UL® 94V-0

Table 2/2


Katalognummer	TRC-400A
Complies With	IEC® 60439.1 IEC® 61439.1 IEC® 60695-2-11 (Glow Wire Test 960 °C)

YDERLIGERE PRODUKTOPLYSNINGER

Thread Size 2 represents input plug.

Line side and load side number of connections are per pole.

DIAGRAMS

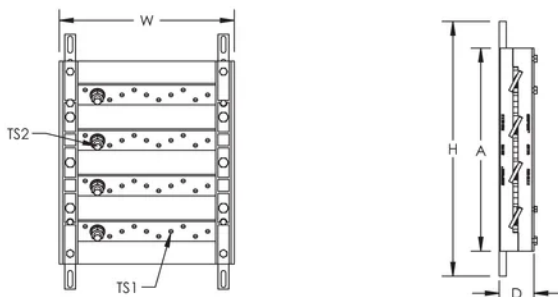

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl,

materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE