

TRS Four Pole Distribution Block, 160 A

Data Solutions



CERTIFICERINGER



FUNKTIONER

- Easily fixes onto asymmetric DIN rail or mounts with screws
- Bolts included for output connections
- Transparent protection cover
- Easy accessibility for wiring
- Ready to use out of the box, saving installation time and labor
- RoHS compliant

SPECIFIKATIONER


Katalognummer	TRS-160A
Artikelnummer	563160
Materiale	Copper Glass Fibre Reinforced Polyamide Plexiglass

Katalognummer	TRS-160A
Max Working Voltage, IEC (Ui)	630
Peak Short Circuit Current (Ipk)	34kA
Short Term Withstand Current (Icw) 1s	13.2kA
Line Side Number of Connections	2
Load Side Number of Connections	4
Hole Size (HS)	8mm
Thread Size (TS)	M6
Dybde (D)	68mm
Height (H)	150mm
Width (W)	230mm
Unit Weight	1.15kg
Flammability Rating	UL® 94V-0
Complies With	IEC® 60439.1 IEC® 61439.1 IEC® 60695-2-11 (Glow Wire Test 960 °C)

YDERLIGERE PRODUKTOPLYSNINGER

Line side and load side number of connections are per pole.

DIAGRAMS

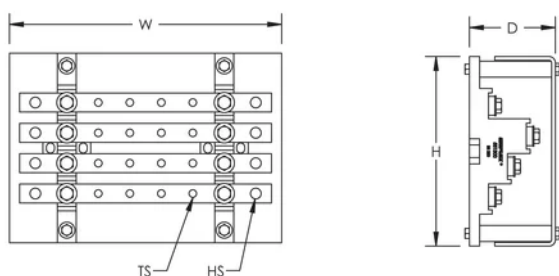

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE