

# Universal Structural Bracket, Strut Brace

## Data Solutions



### CERTIFICERINGER



### FUNKTIONER

Used for installations where strut brace is perpendicular to structure

One wrench size fits all required hardware, eliminating the need to change tools

Shear-off head helps ensure correct torque and simplifies inspection

### SPECIFIKATIONER

**Finish:** Electrogalvanized

**Materiale:** Stål

Table 1/2

Katalognummer	Artikelnummer	Hole Size (HS)	Width (W)	Thickness (T)	A	B
CSBUS1	404568	14.3mm	40.6mm	6.4mm	133.4mm	12.7mm
CSBUS2	404569	20.6mm	40.6mm	6.4mm	133.4mm	12.7mm

Table 2/2


Katalognummer	Artikelnummer	C	D	E
CSBUS1	404568	40.6mm	50.8mm	66mm
CSBUS2	404569	40.6mm	50.8mm	66mm

## YDERLIGERE PRODUKTOPLYSNINGER

Cut length for strut member is +/- 1" (25 mm) of measured length.

FM Loads					
Part Number	Brace Member	Horizontal Capacity per Installation Angle from Vertical			
		30° - 44°	45° - 59°	60° - 74°	75° - 90°
CSBUS1	41 x 41 Strut Channel	8940 N	12630 N	15210 N	16940 N
CSBUS2	41 x 41 Strut Channel	8940 N	12630 N	15210 N	16940 N

## DIAGRAMS

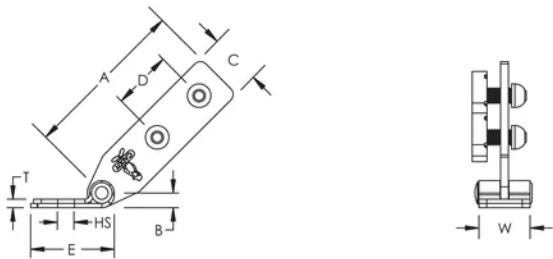

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**