


Non-Insulated Solid Conductor

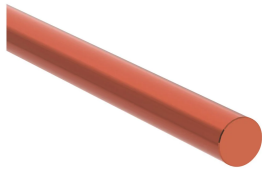

FUNKTIONER

Solid cable for a variety of applications

Available in smaller spool sizes for convenience

LPA and LPC parts are used for lightning protection system downconductor or grounding applications

SPECIFIKATIONER

Table 1/2

Katalognummer	Artikelnummer	Materiale	Finish	Conductor Size	Cross Section	Diameter (Ø)
ASC0850	711530	Aluminium	Bare	8 mm Solid	50.3mm ²	8 mm
RSCC8100	197860	Stål	Hot-Dip Galvanized	1/0 Solid	50.3mm ²	8 mm
RSCC2SS830	197685	Stainless Steel 304 (EN 1.4301)	Bare	1/0 Solid	50.3mm ²	8 mm
RC-ET-8	198210	Copper	Tinned	1/0 Solid	50.2mm ²	8 mm
RC-EC-8	198160	Copper	Bare	1/0 Solid	50.2mm ²	8 mm

Table 2/2

Katalognummer	Artikelnummer	Length (L)	Unit Weight	Complies With
ASC0850	711530	50m	0.14 kg	
RSCC8100	197860	125m	0.4 kg	
RSCC2SS830	197685	30m	0.4 kg	
RC-ET-8	198210	100m	0.45 kg	


Katalognummer	Artikelnummer	Length (L)	Unit Weight	Complies With
RC-EC-8	198160	100m	0.45 kg	IEC® EN 62561-2

YDERLIGERE PRODUKTOPLYSNINGER

Unit weight is per foot (0.3048 m).

Cut-to-order (CTO) lengths are available for an additional charge.

DIAGRAMS

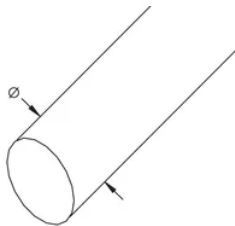

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE