

# Solid Copper Ground Rod, Sectional Internal Thread



## FUNKTIONER

Solid copper sectional ground rod with internal threading

## SPECIFIKATIONER

**Tensile Strength:** 50 MPa

**Materiale:** Copper

Table 1/1


Katalognummer	Artikelnummer	Ground Rod Diameter, Actual (Ø)	Thread Size (TS)	Length (L)	Unit Weight
SCR15	710070	15 mm	M10	1.2m	1.64 kg
SCR20	710080	20 mm	M10	1.2m	3.34 kg

## YDERLIGERE PRODUKTOPLYSNINGER

Due to the inherent softness of the copper material, special consideration should be given when driving this product into the soil.

## DIAGRAMS

---

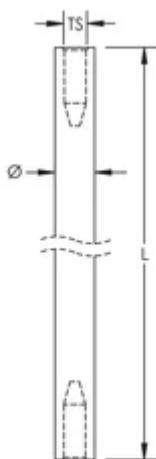

## ADVARSEL

---

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unkladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**