


CABS Module Kit with Neutral

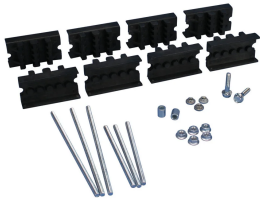

CERTIFICERINGER



FUNKTIONER

Modules provide flexibility to select distance between phases and supports

Installs quickly and easily

Halogen free insulators

RoHS compliant

SPECIFIKATIONER

| | |
|--|---|
| Typical Application Current Rating: | 400 - 4500 A |
| Max Working Voltage, IEC (Ui): | 1000;1500 |
| Working Temperature: | -40 to 130 °C |
| Finish: | Electrogalvanized |
| Materiale: | Stål;Glass Fibre Reinforced Polyamide |
| Complies With: | IEC® 60439.1;IEC® 61439.1;IEC® 60695-2-11 (Glow Wire Test 960 °C) |
| Flammability Rating: | UL® 94V-0 |

Table 1/2

| Katalognummer | Artikelnummer | Busbars per Phase | Busbar Width | Busbar Thickness | Dybde (D) | Width (W) |
|---------------|---------------|-------------------|--------------|------------------|-----------|-----------|
|---------------|---------------|-------------------|--------------|------------------|-----------|-----------|

| | | | | | | |
|----------------|--------|-------|-------------|-------|------|--------|
| CABS4-5TN-MOD | 549340 | 1 - 4 | 30 - 125 mm | 5 mm | 39mm | 75 mm |
| CABS2-10TN-MOD | 549350 | 1 - 2 | 30 - 120 mm | 10 mm | 39mm | 75 mm |
| CABS3-10TN-MOD | 549360 | 1 - 3 | 30 - 120 mm | 10 mm | 39mm | 100 mm |

Table 2/2

| Katalognummer | Artikelnummer | Unit Weight |
|----------------|---------------|-------------|
| CABS4-5TN-MOD | 549340 | 0.5 kg |
| CABS2-10TN-MOD | 549350 | 0.48 kg |
| CABS3-10TN-MOD | 549360 | 0.58 kg |

YDERLIGERE PRODUKTOPLYSNINGER

CABS modules must be installed on CABS-APP Aluminium Profile.

DIAGRAMS



ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE