


# Afskæringsfitting, indlægning, hængslet dæksel

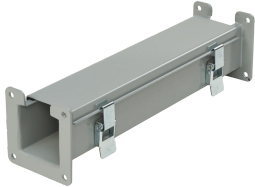

Lay-In Hinged Cover Cutoff Fittings are used for lengths of 9.00 inch (229 mm) to 15.00 inch (381 mm). Body comes in two pieces. Shorten body and cover to the desired length and weld together. Fittings are finished with paint over plated surfaces.

## FUNKTIONER

---

Lay-In Hinged Cover Cutoff Fittings are used for lengths of 9.00 inch (229 mm) to 15.00 inch (381 mm)

Body comes in two pieces. Shorten body and cover to the desired length and weld together

Fittings are finished with paint over plated surfaces

## SPECIFIKATIONER

<b>Farvekode:</b>	ANSI 61
<b>Finish:</b>	Galvaniseret; Struktur Pulvermaling
<b>Farve:</b>	Gray
<b>Materiale:</b>	Lakeret Stål

Table 1/1

Katalognummer	Type	Højde	Bredde	Tykkelse	Tætningsplade type	Antal tætningsplader
F88LXL	Cut-Off Fitting	203mm	203mm	1.9mm	Flat	1
F22LXL	Cut-Off Fitting	64mm	64mm	1.9mm	Flat	1
F126LXL	Cut-Off Fitting	305mm	152mm	1.9mm	Flat	1
F44LXL	Cut-Off Fitting	102mm	102mm	1.9mm	Flat	1
F66LXL	Cut-Off Fitting	152mm	152mm	1.9mm	Flat	1

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**