


# P24 Position Coupler

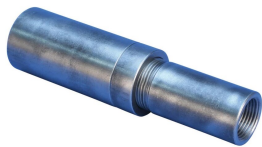

The P24 family of position couplers is designed for use on ASTM A615 grade 100 (700 MPa) reinforcing steel. The performance of the spliced connection is designed to meet the bars' specified ultimate tensile strength of 115 ksi (792 MPa).

## FUNKTIONER

Designed to splice the same diameter bars

Designed to splice two curved, bent or straight bars, when neither bar can be rotated and where the ongoing bar is free to move in its axial direction

## SPECIFIKATIONER

<b>Finish:</b>	Plain
<b>Materiale:</b>	Stål
<b>100% U.S. Domestic Content:</b>	Yes

Table 1/2

Katalognummer	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Length 1 (L1)	Length 2 (L2)
EL57TP24L	57 mm	#18	55M	102 mm	347 mm	375 mm
EL22P24L	22 mm	#7		44 mm	172 mm	188 mm
EL25P24L	25 mm	#8	25M	48 mm	183 mm	199 mm
EL28P24L	28 mm	#9	30M	57 mm	192 mm	208 mm
EL32P24L	32 mm	#10		60 mm	208 mm	224 mm
EL43TP24L	43 mm	#14	45M	80 mm	296 mm	324 mm
EL36P24L	36 mm	#11	35M	70 mm	227 mm	243 mm

Table 2/2


Katalognummer	Bar Depth (BD)	Bar Gap 1 (BG1)	Bar Gap 2 (BG2)	Coupler Body (CB)	Unit Weight	Pakke mængde
---------------	----------------	-----------------	-----------------	-------------------	-------------	--------------

EL57TP24L	83mm	180mm	208mm	188mm	15.5 kg	1
EL22P24L	37mm	98mm	114mm	92mm	1.55 kg	12
EL25P24L	40mm	103mm	119mm	98mm	1.87 kg	8
EL28P24L	42mm	108mm	124mm	104mm	2.85 kg	6
EL32P24L	45mm	118mm	134mm	110mm	3.39 kg	6
EL43TP24L	66mm	164mm	192mm	160mm	8.3 kg	2
EL36P24L	52mm	124mm	140mm	120mm	5.1 kg	5

## YDERLIGERE PRODUKTOPLYSNINGER

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

## DIAGRAMS

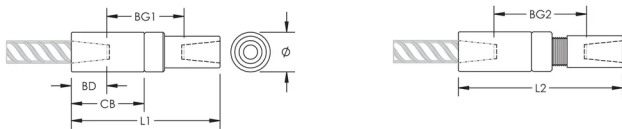

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**