


19" Front Panel for Cable Eyes

19" front panel are for accommodating cable eyes.

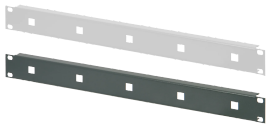

CERTIFICERINGER



FUNKTIONER

19" front panel to accommodate cable eyes (to mount the eyes, insert and rotate them 45°)

SPECIFIKATIONER

Dybde:	1.5mm
Rack Width:	95HP
Accessory Type:	Front panel
Product Type:	Front Panel
Materiale:	Stål

Table 1/2

Katalognummer	Rack Height	Mounting	Pakke mængde	Front Finish	Rear Finish	Farvekode
20118-761	1U	Screw-on Front	1	Painted	Painted	RAL 7035
20118-762	1U	Screw-on Front	1	Painted	Painted	RAL 7021

Table 2/2

Katalognummer	EMC Shielding	Finish	Højde	Type	Bredde
---------------	---------------	--------	-------	------	--------

20118-761	No	Struktur Pulvermaling	43.6mm	19" Front Panel	483mm
20118-762	No	Struktur Pulvermaling	43.6mm	19" Front Panel	483mm

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unkladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE