


19" Front Panel, Plain

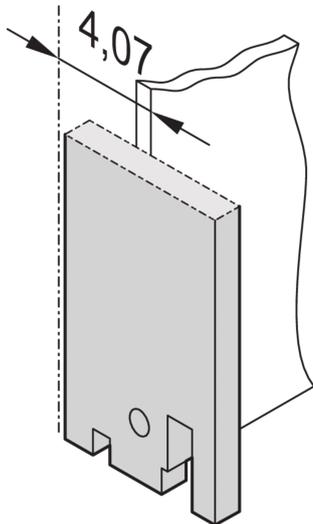

Front panel without or with SUB-D-, ST type 3- or FDDI cut-out.

CERTIFICERINGER



FUNKTIONER

19" Front Panel without Cutout

SPECIFIKATIONER

Dybde:	2.5mm
Materiale:	Aluminium
Accessory Type:	Front panel
Product Type:	Front Panel

Table 1/2

Katalognummer	Rack Height	Rack Width	Pakke mængde	Front Finish	Rear Finish	Farvekode
30118-328	3U	4HP	1	Painted	Conductive	RAL 7035

Katalognummer	Rack Height	Rack Width	Pakke mængde	Front Finish	Rear Finish	Farvekode
30118-331	3U	28HP	1	Painted	Conductive	RAL 7035
30118-330	3U	14HP	1	Painted	Conductive	RAL 7035
30118-329	3U	7HP	1	Painted	Conductive	RAL 7035

Table 2/2

Katalognummer	Finish	Højde	Bredde
30118-328	Struktur Pulvermaling	128.4mm	19.98mm
30118-331	Struktur Pulvermaling	128.4mm	141.9mm
30118-330	Struktur Pulvermaling	128.4mm	70.78mm
30118-329	Struktur Pulvermaling	128.4mm	35.22mm

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unkladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE