


# 19" Front Panel, Vented

Vented front panels allows heat dissipation through holes.

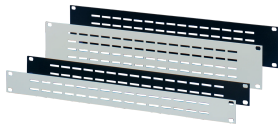

## CERTIFICERINGER



## FUNKTIONER

Vented front panels (Aluminum ) allows heat dissipation

## SPECIFIKATIONER

|                        |             |
|------------------------|-------------|
| <b>Rack Width:</b>     | 95HP        |
| <b>Materiale:</b>      | Aluminium   |
| <b>Accessory Type:</b> | Front panel |
| <b>Product Type:</b>   | Front Panel |

Table 1/2

| Katalognummer | Rack Height | Finish                | Mounting       | Pakke mængde | Front Finish | Rear Finish |
|---------------|-------------|-----------------------|----------------|--------------|--------------|-------------|
| 30118-962     | 1U          | Struktur Pulvermaling | Screw-on Front | 1            | Painted      | Painted     |
| 30702-047     | 1U          | Anodized              | Screw-on Front | 1            | Anodized     | Anodized    |
| 30702-056     | 1U          | Struktur Pulvermaling | Screw-on Front | 1            | Painted      | Painted     |
| 30702-044     | 1U          | Anodized              | Screw-on Front | 1            | Raw          | Conductive  |


| Katalognummer | Rack Height | Finish                | Mounting       | Pakke mængde | Front Finish | Rear Finish |
|---------------|-------------|-----------------------|----------------|--------------|--------------|-------------|
| 30118-963     | 2U          | Anodized              | Screw-on Front | 1            | Painted      | Painted     |
| 30702-048     | 2U          | Anodized              | Screw-on Front | 1            | Anodized     | Anodized    |
| 30702-057     | 2U          | Struktur Pulvermaling | Screw-on Front | 1            | Painted      | Painted     |
| 30118-964     | 3U          | Struktur Pulvermaling | Screw-on Front | 1            | Painted      | Painted     |
| 30702-058     | 3U          | Struktur Pulvermaling | Screw-on Front | 1            | Painted      | Painted     |
| 30702-046     | 3U          | Anodized              | Screw-on Front | 1            | Raw          | Raw         |
| 30702-045     | 2U          | Anodized              | Screw-on Front | 1            | Raw          | Raw         |
| 30702-049     | 3U          | Anodized              | Screw-on Front | 1            | Anodized     | Anodized    |

| Table 2/2     |               |           |               |           |                 |            |
|---------------|---------------|-----------|---------------|-----------|-----------------|------------|
| Katalognummer | Treated Edges | Farvekode | EMC Shielding | Højde (H) | Type            | Bredde (W) |
| 30118-962     |               | RAL 7021  | No            | 43.6mm    | 19" Front Panel | 483mm      |
| 30702-047     | Yes           |           | No            | 43.6mm    | 19" Front Panel | 483mm      |
| 30702-056     |               | RAL 7035  | No            | 43.6mm    | 19" Front Panel | 483mm      |
| 30702-044     |               |           | No            | 43.6mm    | 19" Front Panel | 483mm      |
| 30118-963     |               | RAL 7021  | No            | 88.1mm    | 19" Front Panel | 483mm      |
| 30702-048     | Yes           |           | No            | 88.1mm    | 19" Front Panel | 483mm      |
| 30702-057     |               | RAL 7035  | No            | 88.1mm    | 19" Front Panel | 483mm      |
| 30118-964     |               | RAL 7021  | No            | 132.5mm   | 19" Front Panel | 483mm      |
| 30702-058     |               | RAL 7035  | No            | 132.5mm   | 19" Front Panel | 483mm      |
| 30702-046     |               |           | No            | 132.5mm   | 19" Front Panel | 483mm      |
| 30702-045     |               |           | No            | 88.1mm    | 19" Front Panel | 483mm      |
| 30702-049     | Yes           |           | No            | 132.5mm   | 19" Front Panel | 483mm      |

## YDERLIGERE PRODUKTOPLYSNINGER

Please order 19" assembly kit separately.

## DIAGRAMS

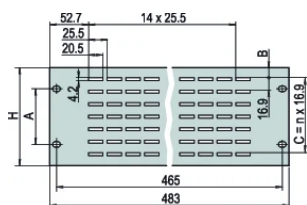

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Vores kraftfulde portefølje af mærker:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**