


# Assembly Parts for Rugged Components

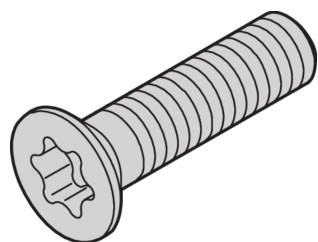

Assembly parts with thread-locking compound for rugged Side Panel, horizontal rail, cover plates, rear angle.

## CERTIFICERINGER



## FUNKTIONER

Screws for the following fixings: Rugged side panel - horizontal rail, Rugged side panel - cover plate, Rugged side panel - rear angle

## SPECIFIKATIONER

**Product Type:** Assembly Kit

**Produktfamilie:** EuropacPRO

Table 1/2

| Katalognummer | Type              | Length | Pakke mængde | Thread Size | Finish | Materiale       |
|---------------|-------------------|--------|--------------|-------------|--------|-----------------|
| 24566-105     | Countersunk Screw | 7mm    | 100          | M4          |        | Stainless Steel |
| 24566-104     | Panhead Screw     | 8mm    | 100          | M4          |        | Stainless Steel |
| 24566-106     | Countersunk Screw | 10mm   | 100          | M4          |        | Stainless Steel |
| 24566-103     | Panhead Screw     | 10mm   | 100          | M4          |        | Stainless Steel |
| 24566-101     | Countersunk Screw | 14mm   | 100          | M4          |        | Stainless Steel |
| 24566-102     | Panhead Screw     | 14mm   | 100          | M4          |        | Stainless Steel |

| Katalognummer | Type              | Length | Pakke mængde | Thread Size | Finish         | Materiale       |
|---------------|-------------------|--------|--------------|-------------|----------------|-----------------|
| 24566-100     | Countersunk Screw | 18mm   | 100          | M4          |                | Stainless Steel |
| 24560-140     | Square Nut        |        | 100          |             | Forzinket Stål | Stål            |

Table 2/2

| Katalognummer | Works With |
|---------------|------------|
| 24566-105     | Subracks   |
| 24566-104     | Subracks   |
| 24566-106     | Subracks   |
| 24566-103     | Subracks   |
| 24566-101     | Subracks   |
| 24566-102     | Subracks   |
| 24566-100     | Subracks   |
| 24560-140     | Subracks   |

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unkladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Vores kraftfulde portefølje af mærker:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**