


# CompacPRO Front/Rear Panel, With Hidden Fixing

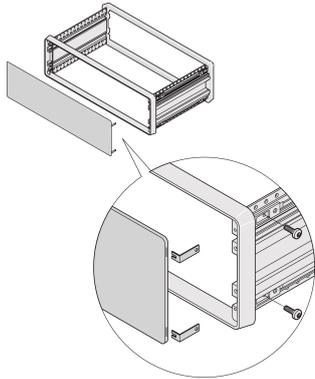

The front panel for CompacPRO Case mounts to the frame of the case. The front panel has no visible screws and can be used for front foil.

## CERTIFICERINGER



## FUNKTIONER

Al panel, 2.5 mm

## SPECIFIKATIONER

<b>Materiale:</b>	Aluminium
<b>Finish:</b>	Anodized
<b>Accessory Type:</b>	Front panel
<b>Product Type:</b>	Front Panel

Table 1/2

Katalognummer	Rack Height	Højde	Rack Width	Bredde	Pakke mængde	Front Finish
24575-275	4U	172.9mm	84HP	452.1mm	1	Anodized
24575-075	2U	84mm	84HP	452.1mm	1	Anodized
24575-155	3U	128.4mm	63HP	345.4mm	1	Anodized

Katalognummer	Rack Height	Højde	Rack Width	Bredde	Pakke mængde	Front Finish
24575-175	3U	128.4mm	84HP	452.1mm	1	Anodized
24575-455	6U	261.8mm	63HP	345.4mm	1	Anodized
24575-475	6U	261.8mm	84HP	452.1mm	1	Anodized
24575-135	3U	128.4mm	42HP	238.7mm	1	Anodized
24575-255	4U	172.9mm	63HP	345.4mm	1	Anodized
24575-035	2U	84mm	42HP	238.7mm	1	Anodized
24575-235	4U	172.9mm	42HP	238.7mm	1	Anodized
24575-115	3U	128.4mm	28HP	167.5mm	1	Anodized

Table 2/2

Katalognummer	Rear Finish	Treated Edges	Dybde
24575-275	Anodized	No	2.5mm
24575-075	Anodized	No	2.5mm
24575-155	Anodized	No	2.5mm
24575-175	Anodized	No	2.5mm
24575-455	Anodized	No	2.5mm
24575-475	Anodized	No	2.5mm
24575-135	Anodized	No	2.5mm
24575-255	Anodized	No	2.5mm
24575-035	Anodized	No	2.5mm
24575-235	Anodized	No	2.5mm
24575-115	Anodized	No	2.5mm

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unndladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Vores kraftfulde portefølje af mærker:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**