


# Countersunk Screw

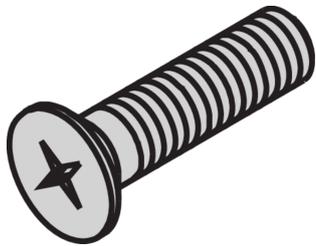

Countersunk screws are used for numerous mounting options in a subrack or desktop case.

## CERTIFICERINGER



## FUNKTIONER

Countersunk screw

## SPECIFIKATIONER

**Product Type:** Screw

Table 1/2

| Katalognummer | Length | Materiale | Finish         | Pakke mængde | Thread Size | Højde |
|---------------|--------|-----------|----------------|--------------|-------------|-------|
| 24560-139     | 5mm    | Stål      | Forzinket Stål | 100          | M4          |       |
| 24560-183     | 12mm   | Stål      | Forzinket Stål | 100          | M5          |       |
| 24560-182     | 12mm   | Stål      | Forzinket Stål | 4            | M5          |       |
| 24560-145     | 14mm   | Stål      | Forzinket Stål | 100          | M4          |       |
| 24560-164     | 8mm    | Stål      | Nickel Plated  | 100          | M2.5        | 4.7mm |
| 24560-158     | 7.7mm  | Stål      | Forzinket Stål | 100          | M2.5        |       |
| 21100-542     | 8mm    | Stål      | Nickel Plated  | 100          | M3          |       |
| 21100-429     | 8mm    | Stål      | Nickel Plated  | 100          | M2.5        |       |
| 21100-649     | 10mm   | Stål      | Forzinket Stål | 100          | M2.5        |       |

| Katalognummer | Length | Materiale | Finish        | Pakke mængde | Thread Size | Højde |
|---------------|--------|-----------|---------------|--------------|-------------|-------|
| 21100-500     | 10mm   | Stål      | Nickel Plated | 100          | M2.5        |       |
| 21100-507     | 12mm   | Stål      | Nickel Plated | 100          | M2.5        |       |

Table 2/2

| Katalognummer | Type              | Bredde | Works With   | Thread Type | Torque |
|---------------|-------------------|--------|--------------|-------------|--------|
| 24560-139     | Countersunk Screw |        | Front Panels |             | 1.3N·m |
| 24560-183     | Countersunk Screw |        | Front Panels |             | 2.4N·m |
| 24560-182     | Countersunk Screw |        | Front Panels |             | 2.4N·m |
| 24560-145     | Countersunk Screw |        | Front Panels |             | 2.4N·m |
| 24560-164     | Countersunk Screw | 4.7mm  | Front Panels | Metric      |        |
| 24560-158     | Countersunk Screw |        | Front Panels |             |        |
| 21100-542     | Screw             |        | Front Panels |             |        |
| 21100-429     | Screw             |        | Front Panels |             |        |
| 21100-649     | Screw             |        | Front Panels |             |        |
| 21100-500     | Screw             |        | Front Panels |             |        |
| 21100-507     | Screw             |        | Front Panels |             |        |

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



Vores kraftfulde portefølje af mærker:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**